

Lip seal for panel

PRFJL **MiniTec** For 2mm thick panels

- Material: black EPDM
- Seal sold by the metre

Uses



- For supporting and sealing 2mm thick panels in profile slots
- Should not be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool
- For panels thinner than 2mm, use 2 PRF-JL-6 seals on either side of the panel instead.

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

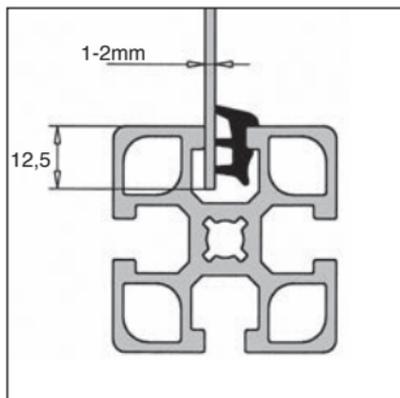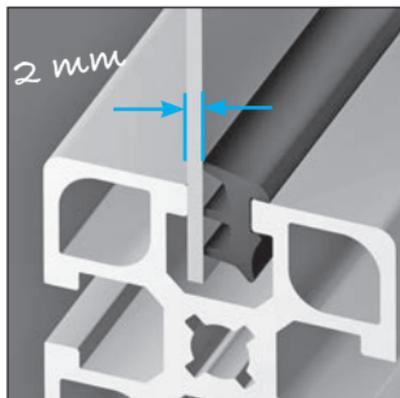

Assembly example

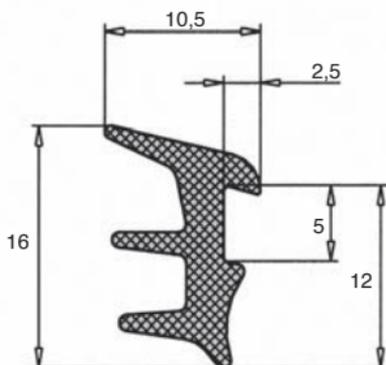

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-2	Lip seal	0,092	3,40 €

Dimensions in mm


Our other products



ZHG5
Plastic spur gear,
Machined plastic
(delrin)



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120 with
counter and han...

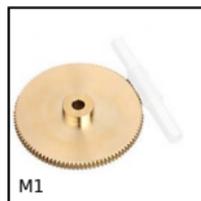

M1
Worm and wheel set,
Bronze



RHTcscs
High Temperature
Castor, up to 200kg



AC
Strike for toggle latch,
18mm



SC2
2 part rigid shaft
clamp, Clamping jaw



MPS
Hexagonal spacer,
Stainless steel 303



UGH32
H Type Guide units,
For Ø32 actuators



CHMR50
Worm and wheel gear
reducer, up to 107



RFK48C
Hypoid gearbox -
Stainless steel, up to



SERB
Universal latch key,
Universal latch key



GCT
Pipe lynch pin, Tube
lynch pin

Complementary products



PRF4545
Standard aluminium
profile, 45 x 45 mm