

# Lip seal for panel

PRFJL **MiniTec** For 2mm thick panels

- Material: black EPDM
- Seal sold by the metre

## Uses



- For supporting and sealing 2mm thick panels in profile slots
- Should not be used with acrylic or polycarbonate panels

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool
- For panels thinner than 2mm, use 2 PRF-JL-6 seals on either side of the panel instead.

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

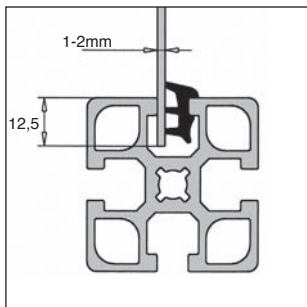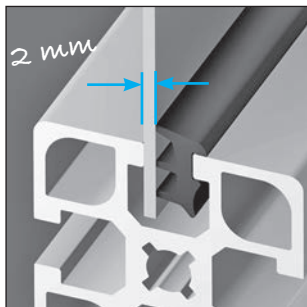

Assembly example

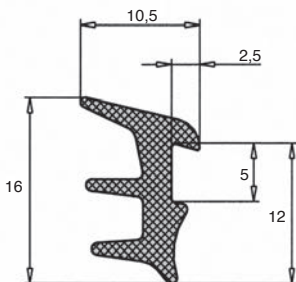

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-2	Lip seal	0,092	3,40 €

Dimensions in mm

## Our other products



Horizontal stirrup toggle clamp,  
Horizontal stirrup clamp - steel



Swivel castor with double brake,  
Stainless steel - Polyamide



Storage bin, 8mm



Machined plastic bevel gear , 1:1



Utilitak® V rail, V rail



Accessories, Fixing kit



Cell carrier assembly,  
Ready assembled



Manual bonnet fastener, Black rubber fastener



 
Narrow spur rack,  
Steel



Moulded plastic bevel gear (nylon), 3:1



High Temperature Castor, up to 200kg



Indexing plunger mini, miniature - Stainless steel

## Complementary products



Standard aluminium profile, 45 x 45 mm