

Lip seal for panel

PRFJL **MiniTec** For 2mm thick panels

- Material: black EPDM
- Seal sold by the metre

Uses



- For supporting and sealing 2mm thick panels in profile slots
- Should not be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool
- For panels thinner than 2mm, use 2 PRF-JL-6 seals on either side of the panel instead.

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

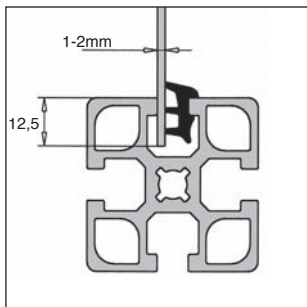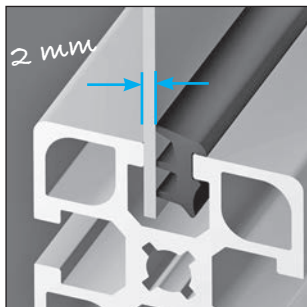

Assembly example

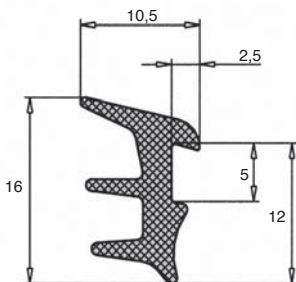

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-2	Lip seal	0,092	3,40 €

Dimensions in mm

Our other products



PM4

Worm and wheel set,
Hardened steel



PP50

Worm and wheel gear
reducer, from 6.50 to
12.80 Nm



TK_UUOP

Topball self-aligning
linear bearing, Topball
self-aligning



BLHM40

Right angled gearbox,
double output shafts,
up to 10.3 Nm



CHAK

Hi-Klik TM indent
hinge, Hi-Klik™ -
Detent hinge




PSG2

Spur gear - precision
range, Case hardened
steel 20NCD2



M2

Worm and wheel set,
Machined plastic
(delrin)

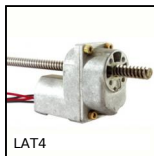

LAT4

4A motorised linear
actuator, 4 amperes




INS150

Self tapping insert
with collar-coarse



VPRA_M

 Handwheel with
handle,



PB

Plastic deep groove
ball bearing, Plastic -



AT10-BAR

AT type tooth bar
stock, AT10

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm