

Lip seal for panel

For 4mm thick panels

MiniTec PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 2-4mm thick panels in profile slots
- Can be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of a perture to ensure panel will be supported correctly

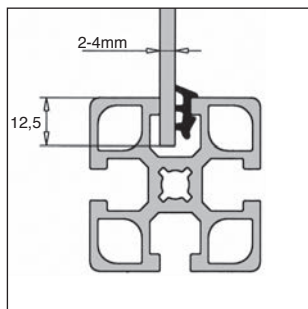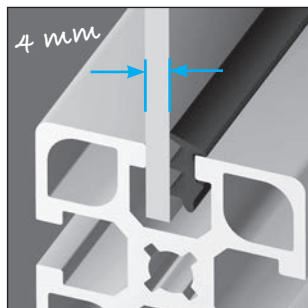

Assembly example

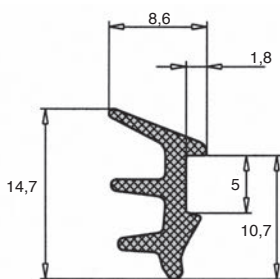

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-4	Lip seal	0,065	2,32 €

Dimensions in mm

Our other products



ZDB
Machined plastic
bevel gear , 2:1



PW_PWG15
Worm - precision
range, Stainless steel



ACLRP
Wheel for aluminium
profile, Integrated
bearing



PAT123
Pressed stainless
steel articulating foot
Ø123, Ø123



PCS8ECO
Chain sprocket - steel,
8mm (DIN 05B-1)



PRF_CHA
Hinge for aluminium
profile, Surface
mounting hinge



RURp
Wheel pivoting with
plate, Polyurethane -
Aluminium rim (Free
running)



ERT
Sliding nut, For T slot



CNA-CNG
Right angled
mounting plate, Right
angled mounting



PTRSS
Idle chain sprocket,
For hostile
environments



TK_UUOP
Topball self-aligning
linear bearing, Topball
self-aligning



RPCtcss
Swivel castor with
central hole, Stainless
steel - Polyamide

Complementary products



PRF4545
Standard aluminium
profile, 45 x 45 mm