

Lip seal for panel

For 4mm thick panels

MiniTec PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 2-4mm thick panels in profile slots
- Can be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of a perture to ensure panel will be supported correctly

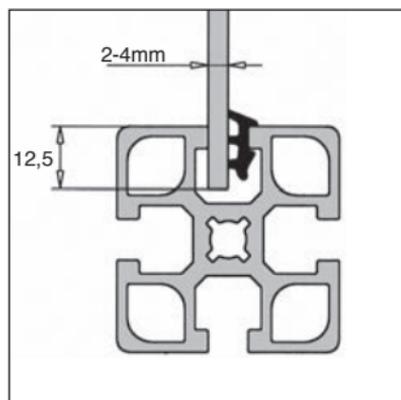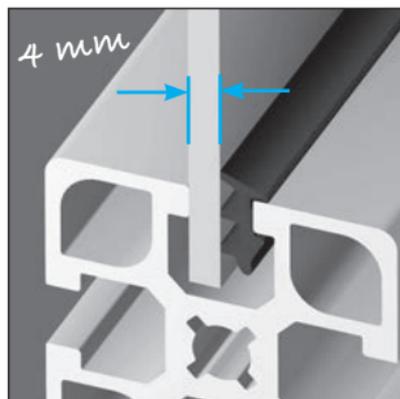

Assembly example

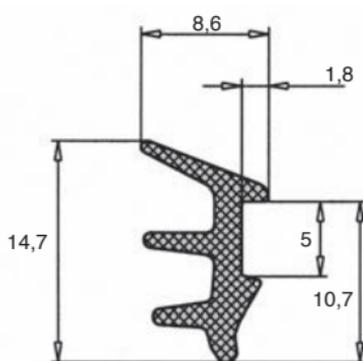

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-4	Lip seal	0,065	2,32 €

Dimensions in mm

Our other products



RT25
Self-centering flanged locking assembly, Medium/high torque




CHA225
Screwed hinge with threaded insert, 225 degrees



PF40NM
Worm and wheel gear reducer, up to 18 Nm



ACLEPP
Right angled bracket for aluminium profile, 4 holes

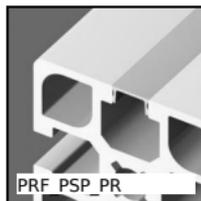


PRF_PSP_PR
Dual purpose strip and cover for aluminium profile, Inserts into slot



WJUM10
Drylin® W bearing block, Slide



PM2
Worm, Machined plastic (delrin)

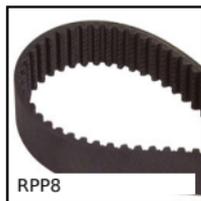

RPP8
RPP heavy duty timing belt, RPP8



BLHB40
Right angled gearbox, bored shafts, up to 10.3 Nm



PTKss
Foot for the food industry, Stainless steel - 3-A standard



SSB
Stainless steel bevel gear, 1:1



PSG1
Spur gear - precision range, Case hardened steel 20NCD2

Complementary products



PRF4545
Standard aluminium profile, 45 x 45 mm