

Lip seal for panel

For 4mm thick panels

MiniTec PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 2-4mm thick panels in profile slots
- Can be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of a perture to ensure panel will be supported correctly

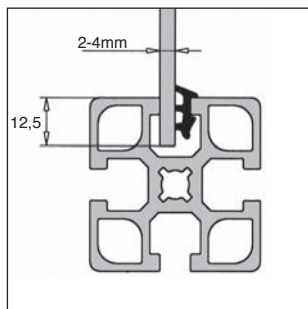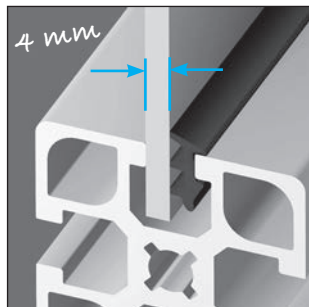

Assembly example

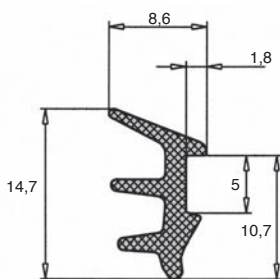

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 50+ | 100+ |
| Disc. | List | -5% | On request |

| Part number | Type | Weight (kg/m) | Price per metre |
|-------------|----------|---------------|-----------------|
| PRF-JL-4 | Lip seal | 0,065 | 2,32 € |

Dimensions in mm

Our other products



ECF

Well nut, Chloroprene elastomer



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm



NCT

Square tube connector, Fixed angle



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard



UTKswrr

V shaped channel UtiliTrak®, V rail



BDP2R

Adjustable support arm, Increased grip



BPPss

Pressed stainless steel pillow block, Stainless steel



IN1

Internal gear, Steel 20NCD2



RFK38B

Hypoid gearbox - Stainless steel, up to 5500 Nm



SUA4

Single chain supplied by the metre, Steel



SH0

Parallel axis helical gear, Steel 20NCD2



G-ECO

Eco range Spur gear, Steel C45

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm