

Lip seal for panel

For 4mm thick panels

MiniTec PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 2-4mm thick panels in profile slots
- Can be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of a perture to ensure panel will be supported correctly

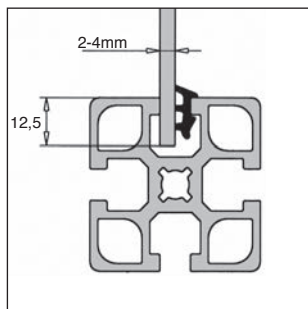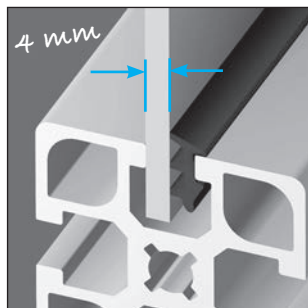

Assembly example

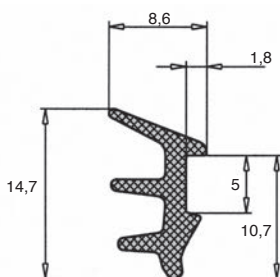

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-4	Lip seal	0,065	2,32 €

Dimensions in mm

Our other products



AKN

Bellows coupling Gerwah®, from 22 to 180Nm



PSG15

Spur gear - precision range, Stainless steel 303



ZG125

Plastic spur gear, Machined plastic (delrin)



CHA60

Rectangular hinge, drilled or countersunk, Rectangular, drilled or C...



PAMF80EB

Articulated foot with sheet metal base Ø80, Articulated foot



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



PLM-SC

Magnetic stud with central countersunk hole, With milled bore



SVT5

Screwjack with travelling screw, with translating screw




ES

Simple support base (bipod), Plastic



PGM86-M5

Pull handle, Thermoplastic

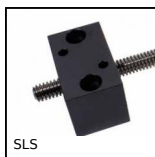

SLS

Bearing block for leadscrew, Fixed



DBL805

Idler for slat top chain, Range 805

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm