

# Lip seal for panel

PRFJL **MiniTec** For 5mm thick panels

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 5mm thick panels in profile slots
- Can be used with plexiglas or polycarbonate panels

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

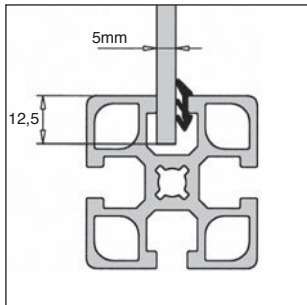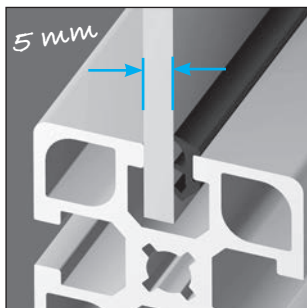

Assembly example

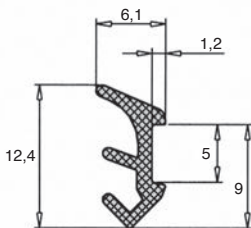

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-5	Lip seal	0,033	2,01 €

Dimensions in mm

 
## Our other products



Stainless steel Dee shackle with eye bolt, Stainless steel



Right angled gearbox, bored shafts, up to 1.77 Nm



RPP heavy duty timing belt, RPP5



Straight clevis, Straight clevis for use with a male clevis



 
Pull handle, Steel



Weld-on hinge with flat end, Stainless steel or Aluminium



Threaded rod - DIN975, Stainless steel A2



Double row angular contact ball bearing, Angular contact - Steel



Spur gear - precision range, Pre-hardened Steel 35NCD6



Rounded end feather key, Stainless steel



Plastic clamping collar, Ø25 - Ø40



Ball transfer unit housed spring loaded, High

## Complementary products



Standard aluminium profile, 45 x 45 mm