

# Lip seal for panel

PRFJL **MiniTec** For 5mm thick panels

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 5mm thick panels in profile slots
- Can be used with plexiglas or polycarbonate panels

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

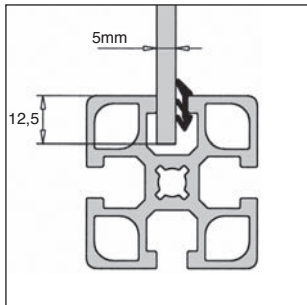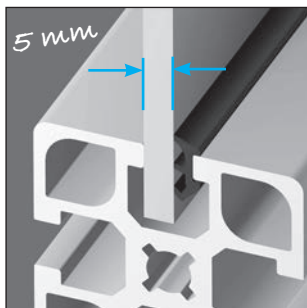

Assembly example

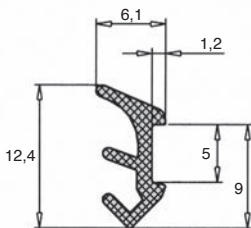

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-5	Lip seal	0,033	2,01 €

Dimensions in mm

## Our other products



CAP881

Side flexing slim slat top chain stainless steel, Narrow range 881



AT10-32ECO

AT type timing pulley, Economy range - AT10 aluminium



 
SKM

Hexagonal steel nut, Steel - 1 thread



F7-5N

Multifunction display, Articulated support



ACLCHAR

Hinge for aluminium profile, With elongated holes



T25-6ECO

T type timing pulley, Economy range - T2.5 aluminium



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



PSG125S

Spur gear - precision range, Stainless steel 303



 
UTKswrr

V shaped channel UtiliTrak®, V rail



GARBAB

Lock pin for clamping, Ball lock pin



PF20NM

Worm and wheel gear reducer, up to 5 Nm



BLHB20

Right angled gearbox, bored shafts, up to 1.77 Nm

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm