

Lip seal for panel

PRFJL **MiniTec** For 5mm thick panels

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 5mm thick panels in profile slots
- Can be used with plexiglas or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

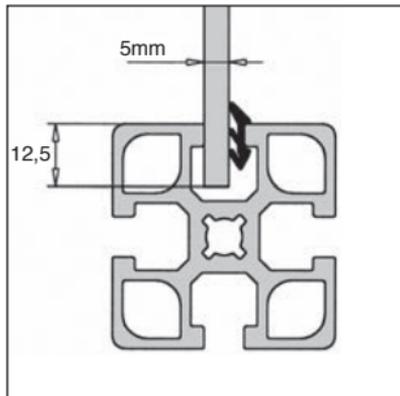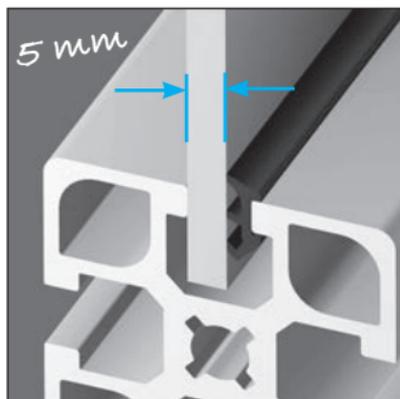

Assembly example

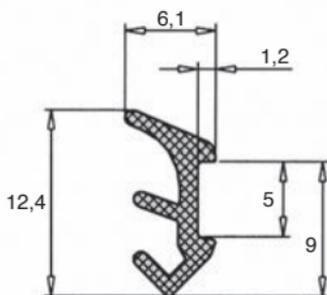

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-5	Lip seal	0,033	2,01 €

Dimensions in mm

Our other products



ADL_M

Male eye bolt conforms to DIN580, Stainless steel



GLT3-46A

Telescopic drawer with damper,



CHAE3030PA

Square decorative screwed hinges, Polyamide



UFX

Uneflex® elastic coupling, economy range



RBS

Dynamic washer DIN2093, Steel



PX_PO

Carrying handle, standard



BABreceptacle

Ball pin socket, Socket



SHA

Handwheel without handle, Polyamide



DER63

Stainless steel AC asynchronous motor



HD

Double needle roller universal joint, Heavy



T10_30_AL

T type timing pulley, Economy range - T10



TCL-ECL

Support rod for heavy loads, Support spindle

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm