

# Lip seal for panel

For 6mm thick panels

**MiniTec**PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 6mm thick panels in profile slots
- Can be used with plexiglass or polycarbonate panels
- Can also be used to support panels thinner than 2mm by using a seal on each side

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

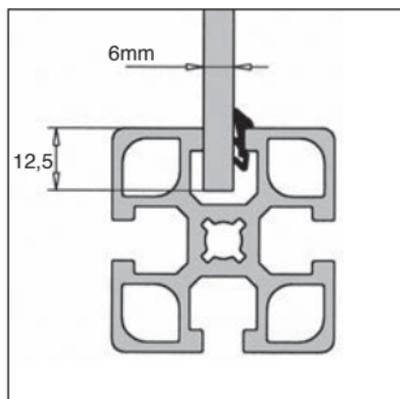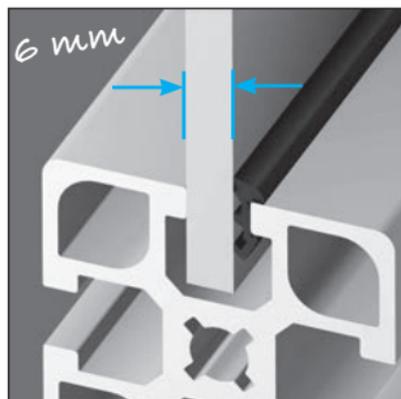

Assembly example

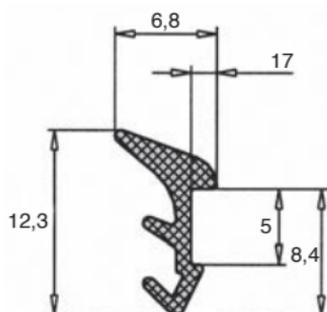

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-6	Lip seal	0,033	1,68 €

Dimensions in mm

## Our other products



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



AC

Strike for toggle latch, 15mm



FB\_ECO

Eco. range steel bevel gear, 4:1



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



PF40

Worm and wheel gear reducer, up to 18 Nm



SHS

Shoulder screw stainless steel 303, Stainless steel 303




WSSss

Symmetrical S shaped hook stainless steel, Stainless steel



RBNpl

Swivel caster with plate, Steel - rubber

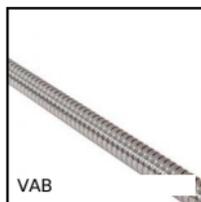

VAB

Ballscrew, supplied by the metre, Rolled ballscrew, per metre




TIF

Threaded rod - DIN975, Stainless steel A2



KB\_UU

Closed linear precision bearing, Precision - steel

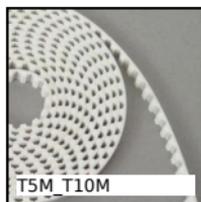

T5M\_T10M

T type timing belt per metre, T5 Steel cored polyurethane

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm