

# Lip seal for panel

For 6mm thick panels

**MiniTec**PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 6mm thick panels in profile slots
- Can be used with plexiglass or polycarbonate panels
- Can also be used to support panels thinner than 2mm by using a seal on each side

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

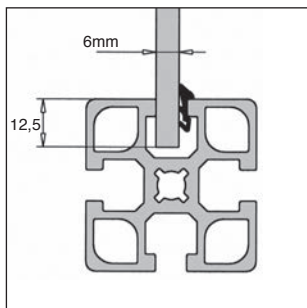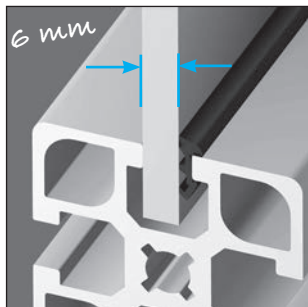

Assembly example

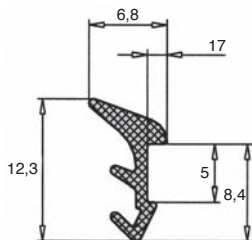

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-6	Lip seal	0,033	1,68 €


Dimensions in mm

## Our other products



TAC\_SS

Stainless steel rigging screw (hook/eye),  
Stainless steel

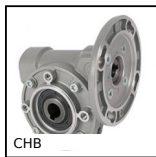

CHB

Worm and wheel gear reducer, up to 41 Nm




HLA19

Right angle spiro bevel gearbox, Up to 43Nm



BFA

 Shaft locking washer, E clip



CYS

Internal circlip  
DIN472, internal DIN 472



STRIPF

Sealing brush strip,  
1m length



ACLAPA

Magnetic stop for aluminium profile,  
Magnetic stop



MLY\_SS

Stainless steel bow shackle with eye bolt,  
Stainless steel



GPB

Threaded spherical knob, With brass insert



PRF\_PF

Anchoring bracket for aluminium profile,  
Anchor



KSTM

Igubal® pillow block bearing, Polymer



ACLBMC

Detector support for aluminium profile,  
Sensor holder

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm