

# Lip seal for panel

For 6mm thick panels

**MiniTec**PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 6mm thick panels in profile slots
- Can be used with plexiglass or polycarbonate panels
- Can also be used to support panels thinner than 2mm by using a seal on each side

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

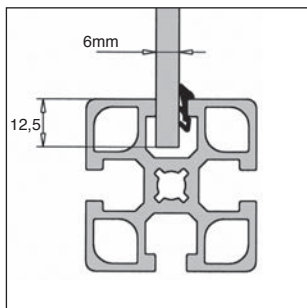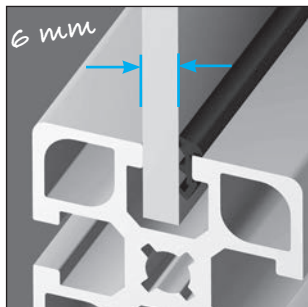

Assembly example

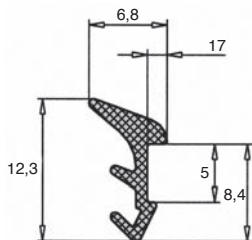

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-6	Lip seal	0,033	1,68 €

Dimensions in mm

## Our other products



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



ATZY

Diablo shaped elastomeric mount, Steel



MEB

Moulded plastic bevel gear (nylon), 1:1



DBL880

Idler for slat top chain, Ranges 880 and 881



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - stainless steel



SCR

Suction cup threaded insert, Adaptator for insert



BLHT50

Right angled gearbox, from 11.50 to 30 Nm




SH0

Parallel axis helical gear, Steel 20NCD2



PTKFss

 Fixable foot for the food industry, Stainless steel - 3-A



R\_RR

Narrow spur rack, Steel



PSG15S

Spur gear - precision range, Stainless steel 316



CSSSS

Stainless steel spherical bearing, Stainless steel / PTFE

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm