


- Supplied with profile fixing kit
- Material: grey powder covered steel

Uses


- For attaching panels or chassis to floors
- Suitable for all profiles up to 45x45mm

Assembly

- Insert the profile into the foot
- Insert nuts with sprung tabs into the slots on the profile and lightly tighten the screws
- Make final adjustments to the position of the profile and then firmly tighten the screws
- Use anchoring system if fixing to a floor

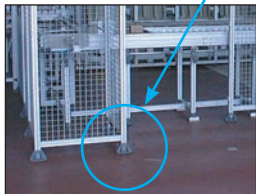

Typical application

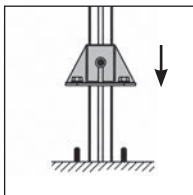

Mounting example


DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-P-45	Anchor	0,595	✓	20,24 €

*Depending on availability - Dimensions in mm

 Our other products



BH02

Single housed bearing assembly, Bearing secured with circlips



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80 with counter and handw...



BLM

Spring loaded plunger with ball tip, Stainless steel body



SLV

Vertical toggle clamp, Vertical Lever Clamp - stainless steel



PF55

Worm and wheel gear reducer, up to 57 Nm



PLM-SC

Magnetic stud with threaded hole, With threaded hole



RBGpl

Swivel castor with plate, Steel - grey rubber



DB

Steel bevel gear, 2:1



BPFss

Pressed stainless steel flange bearing, Stainless steel



LRRss

Latch, Spring loaded latch - stainless steel



NAST

Cam follower without axial guide, With interior ring



PTKss

Foot for the food industry, Stainless steel - 3-A standard

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm