

Internal hinge pin for aluminium profile

MiniTecPRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

Uses



- Doors
- Panels
- Sections of structures that need to move

Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten. Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grubscrews on each hinge

Info.

- Max. load: 250N

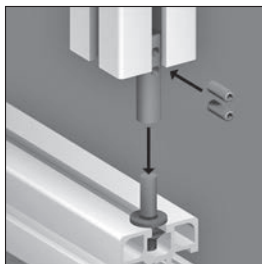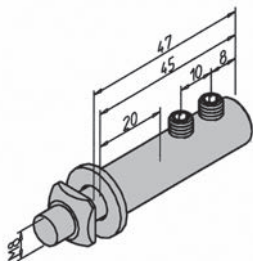

Typical application



DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	8,28 €

*Depending on availability - Dimensions in mm

Our other products



BAC105

Storage bin, 8mm



BEAS

Star shaped anti-static handle, Star, anti-static



CLM

Male clevis end, Steel short



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



PRES7HR

Manual workbench press, Force up to 700kg



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - steel



SHW

Plain washer, Steel



BEAB

Knob star grip antibacterial, Star, anti-bacterial



SH0

Parallel axis helical gear, Steel 20NCD2



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ART

Articulated bracket for use with aluminium profile, With clamping ha...