

# Internal hinge pin for aluminium profile

## MiniTecPRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

### Uses



- Doors
- Panels
- Sections of structures that need to move

### Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten.
- Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

### Info.

- Max. load: 250N

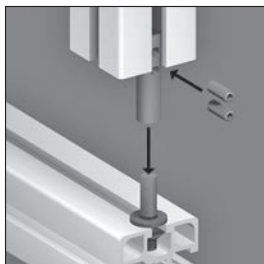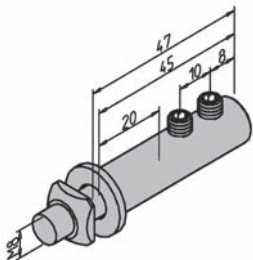

Typical application



### DISCOUNTS

Qty	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	8,28 €

\*Depending on availability - Dimensions in mm

## Our other products



BPPL

Mini plain bearing ball transfer unit, For countersinking



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



VTAP

Magnetic head screw, With rubber coating  
With rubber coating



MPS

Hexagonal spacer, Stainless steel 303



STL

Guidance brush - Rail, Rail



PHT

Pull handle, Up to 250 °C



PW\_PWG05

Worm - precision range, Stainless steel



H02SS

Needle roller universal joint - Stainless steel,



PM4

Worm and wheel set, Bronze



CHA38\_SS

Stainless steel face frame hinge, Surface



PITA

Locking bolt, with T handle

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF\_ART

Articulated bracket for use with aluminium profile, With clamping ha...