

Internal hinge pin for aluminium profile

MiniTecPRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

Uses



- Doors
- Panels
- Sections of structures that need to move

Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten.
- Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

Info.

- Max. load: 250N

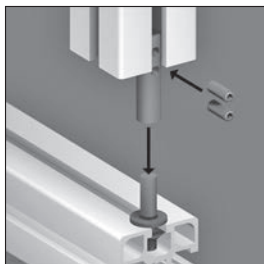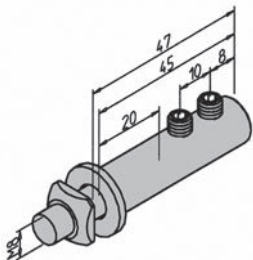

Typical application



DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	8,28 €

*Depending on availability - Dimensions in mm

Our other products



PTAF80-PAMF80
Articulated fixable foot with pressed base Ø80, Ø 80



BOXdh
Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



PP50
Worm and wheel gear reducer, from 6.50 to 12.80 Nm



PRF_ER
Joining bar for aluminium profile, Joint bar



STRIP1000
Sealing brush strip, 1m length



SH0
Parallel axis helical gear, Steel 20NCD2



DFG
Flat suction cup, silicon



GGB
Female wing knob, Fully threaded



CHTRP
Single and dual output gearboxes, Up to 9,1 Nm



LVT
Miniature motorised actuator 4A, 4 ampers



SCR
Suction cup threaded insert, Adaptor for insert



GAL48_OMNI
Omni-directional roller, Omni-directional

Complementary products



PRF4545
Standard aluminium profile, 45 x 45 mm



PRF_ART
Articulated bracket for use with aluminium profile, With clamping ha...