

Internal hinge pin for aluminium profile

MiniTecPRFPiv

- Supplied with fixing kit
- Material: anodised aluminium

Uses



- Doors
- Panels
- Sections of structures that need to move

Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten. Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

Info.

- Max. load: 250N

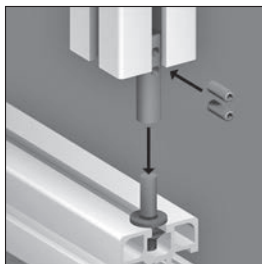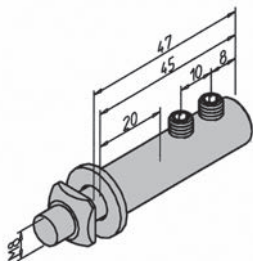

Typical application



DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-Piv	Hinge pin	0,02	✓	8,28 €

*Depending on availability - Dimensions in mm

Our other products



BCM_T
Driving collar, Driving collar



TCXR
Automatic chain tensioner, With stainless steel sprocket



PCF4
Conical flexible mount, Square base plate



BOXKK
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



DOG111
Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



WJUM10
Drylin® W bearing block, Slide



ESST
Tripod support base, Tripod support base



WTM
Tightening washer - DIN6340, Steel



SCA_SS
Stainless steel flat cable clamp, Stainless steel



MHPGR
Arm with folding rotating handle, rotating handle



PRF_ECL
Nut for aluminium profile, Stainless steel square nut with tab



Q4
Double row radial contact ball bearing, Radial contact - Steel

Complementary products



PRF4545
Standard aluminium profile, 45 x 45 mm



PRF_ART
Articulated bracket for use with aluminium profile, With clamping ha...