

# Internal hinge pin for aluminium profile

## MiniTecPRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

### Uses



- Doors
- Panels
- Sections of structures that need to move

### Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten.
- Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

### Info.

- Max. load: 250N

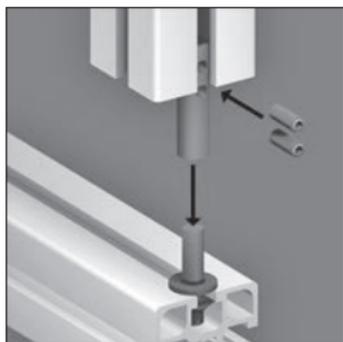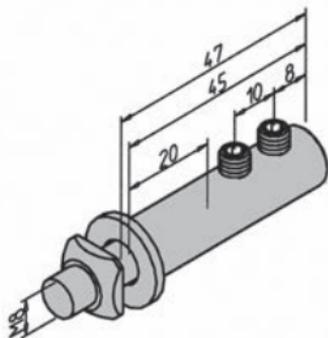

Typical application



### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	8,28 €


\*Depending on availability - Dimensions in mm

## Our other products




JCDss

Double universal joint  
- Stainless steel, Low  
duty

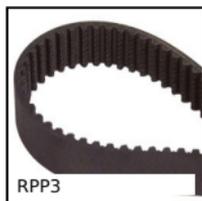

RPP3

RPP heavy duty  
timing belt, RPP3

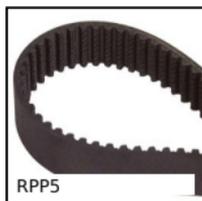

RPP5

RPP heavy duty  
timing belt, RPP5



PDD

Actuating plunger,  
Non-rotating detector  
shaft



CHAR5050\_Z

Spring hinge, screwed



QTR

Tapered roller  
bearing, Steel



PR125

Articulated foot Ø123,  
Ø 123



NPTR\_M

Adjustable cross  
clamp, Adjustable



VHEH

Hexagonal headed  
screw with collar  
Hygienic Usit®,



SBF

Sealed flange bearing  
unit for Food Industry,  
cover



GMK17\_BR

Clamp for guiding  
profile, Rounded only  
- single



NCT

Square tube  
connector, Fixed  
angle

## Complementary products



PRF4545

Standard aluminium  
profile, 45 x 45 mm



PRF\_ART

Articulated bracket for  
use with aluminium  
profile, With clamping ha...