

Internal hinge pin for aluminium profile

MiniTec PRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

Uses



- Doors
- Panels
- Sections of structures that need to move

Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten. Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

Info.

- Max. load: 250N

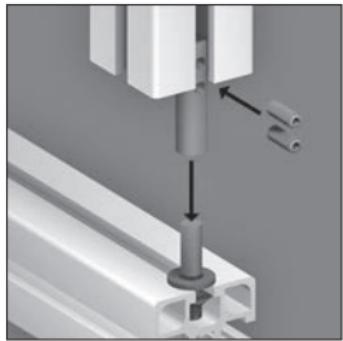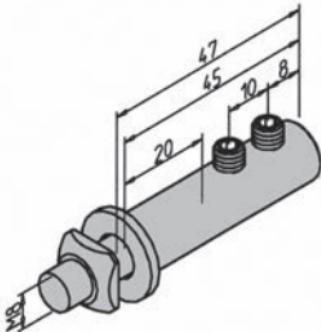

Typical application



DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	8,28 €

*Depending on availability - Dimensions in mm

Our other products



MRA
Quick link, Steel



FF15
Offset spur gear
reducer, from 2.20 to
10 Nm



NCT
Square tube
connector, Fixed
angle



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10




BPHF
Ball transfer unit push
fit, Heavy



PSG2
Spur gear - precision
range, Case hardened
steel 20NCD2



CMM_SS
Male rod ends DIN
ISO12240-4, Stainless
steel / bronze -
Economy range

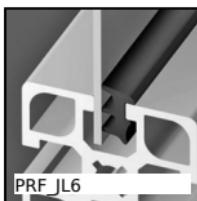

PRF_JL6
Lip seal for panel,
Door seal - Ø 6mm



ZHBRA
Plastic bevel gear,
1,25:1 2:1 3:1



ACLEPP
Right angled bracket
for aluminium profile,
4 holes



BPLE
Ball transfer unit push
fit, Light



VRBS
Folding lifting ring for
welding, Folding - for
welding

Complementary products



PRF4545
Standard aluminium
profile, 45 x 45 mm



PRF_ART
Articulated bracket for
use with aluminium
profile, With clamping
ha...