

# Fastener for aluminium profile

Stock


## PRF **MiniTec**

### Standard fastener

#### FIXSTD

#### Profile assembly

- Suitable for loads up to 18000N
- Can be used to securely join all profile types
- Forms very efficient anti-twist joint
- Materials:
  - M8x50mm CHC screw: electroplated steel
  - Locking plate: electroplated steel


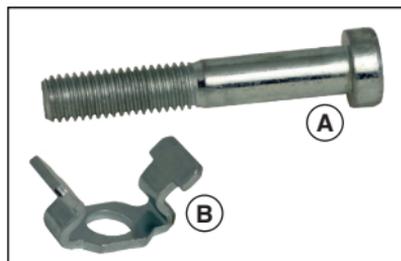


#### Applications

- For heavy or vibrating loads

#### Assembly

- Drill a stepped hole ( $\varnothing 9$ ,  $\varnothing 15$ ) at the required position ①
- Slide the screw locking plate in the slot
- Pass the end of the screw through the first profile ①, the locking plate and then into the central hole of the second profile ② which was previously tapped (M8 x 25mm) and tighten.

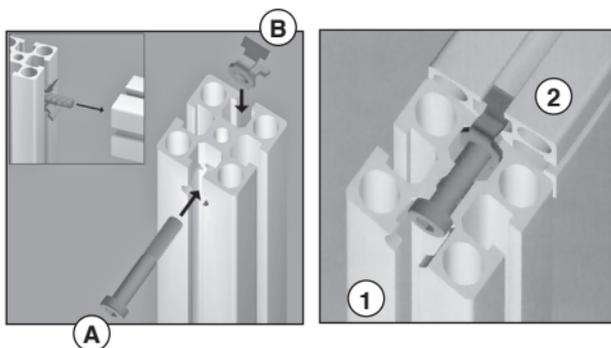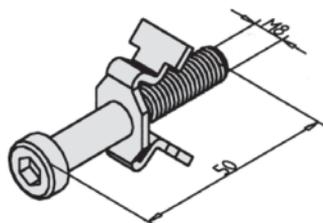

#### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Load (N) | For profile              | Tightening torque (Nm) | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|----------|--------------------------|------------------------|-------------|--------|--------------------|
| PRF-FIX-STD | 18000    | All types of PRF profile | 20                     | 0,03        | ✓      | 2,94 €             |

\*Depending on availability - Dimensions in mm




- Square nut with sprung tab
- Nut can be inserted at any point along the slot in a profile
- Material: zinc plated or stainless steel
- Not sold individually, contact us for details

steel or stainless steel



### Advantages

- Allows parts to be added/removed easily
- Sprung tabs allows the nut to be retained in place when using vertically positioned profiles

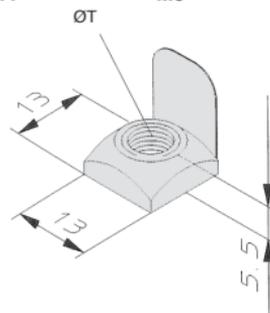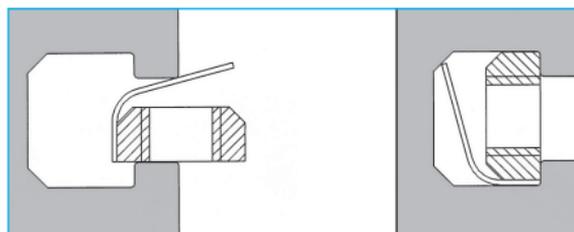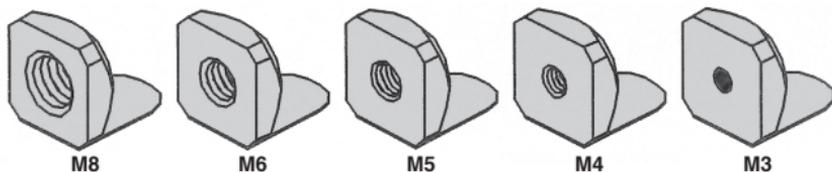

Very simple to position

### DISCOUNTS

|            |     |            |      |
|------------|-----|------------|------|
| Qty        | 1+  | 50+        | 100+ |
| Disc. List | -5% | On request |      |

| Part number |                 | ØT | Stock*<br>Steel | Price each 1 to 49 |                 |
|-------------|-----------------|----|-----------------|--------------------|-----------------|
| Steel       | Stainless steel |    |                 | Steel              | Stainless steel |
| PRF-ECL-M3  | PRF-ECL-M3/SS   | M3 | ✓               | 1,17 €             | 3,14 €          |
| PRF-ECL-M4  | PRF-ECL-M4/SS   | M4 | ✓               | 1,17 €             | 3,14 €          |
| PRF-ECL-M5  | PRF-ECL-M5/SS   | M5 | ✓               | 1,17 €             | 3,14 €          |
| PRF-ECL-M6  | PRF-ECL-M6/SS   | M6 | ✓               | 1,17 €             | 3,34 €          |
| PRF-ECL-M8  | PRF-ECL-M8/SS   | M8 | ✓               | 1,17 €             | 3,31 €          |

\*Depending on availability - Dimensions in mm

# Hammerhead screw

Stock

PRFV<sup>TM</sup> **MiniTec**



- Screws can be inserted at any point along the slot in the profile.
- Material: zinc plated steel
- **Not sold individually, contact us for details**

## Advantages


- Hammerhead screws are a simple way of adding components or accessories onto profiles that have already been assembled

## Assembly

- Place the screw in the slot at the required position, mount the accessory to be added and tighten the M8 nut
- Tightening the nut causes the screw to become perpendicular to the slot.

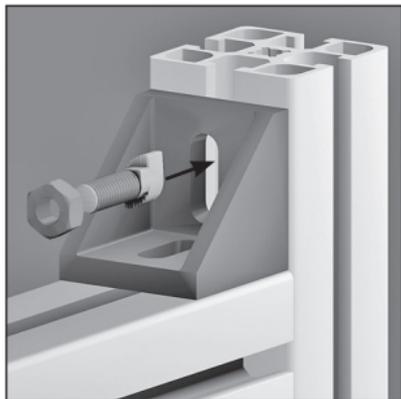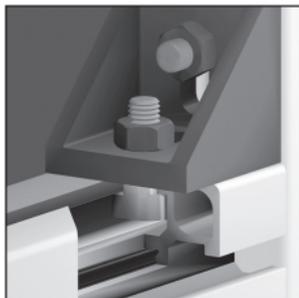

Typical application

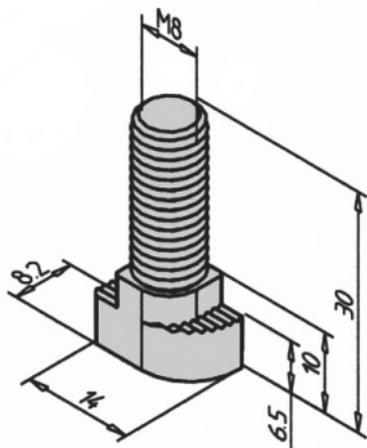

## DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Type             | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|------------------|-------------|--------|--------------------|
| PRF-VTM-M8  | Hammerhead screw | 0,012       | ✓      | 1,64 €             |

\*Depending on availability - Dimensions in mm


- Material: electroplated steel
- 4 electroplated M8 x14mm grub screws (use SW4 hexagonal key or PRF-TOOL-H4 tool) (tome 5 p.322)

### Uses


- For but joining profiles.
- For creating longer profiles

### Assembly

- Simply twist into slot in profile
- No preparation required
- For long profiles or to support heavier loads, use more joining bars.

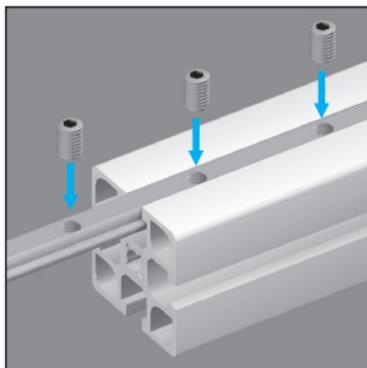

Typical application

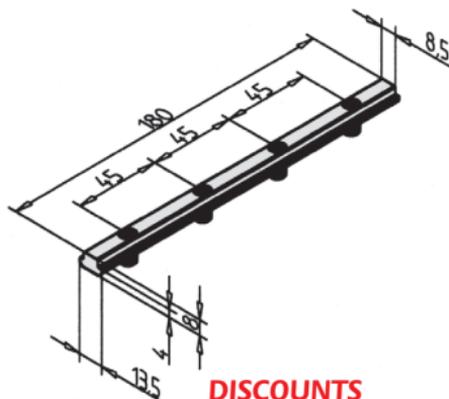

### DISCOUNTS

| Qty   | 1+   | 50+ | 100+       |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | Type        | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|-------------|--------|--------------------|
| PRF-ER-180  | Joining bar | 0,12        | ✓      | 19,78 €            |

\*Depending on availability - Dimensions in mm

# Joining plate for aluminium profile Stock

## PRF<sub>PL</sub> **MiniTec** For joining pre-assembled structures




- For joining two structures together
- Ensures rigid and stable installation of protective barriers
- Mounting kit supplied
- Material:  
Grey powder coated aluminium GD

### Assembly

- Use the fixing kit to attach to the mounting slot on the protective panel and the slot on the support profile



Grey powder coated aluminium

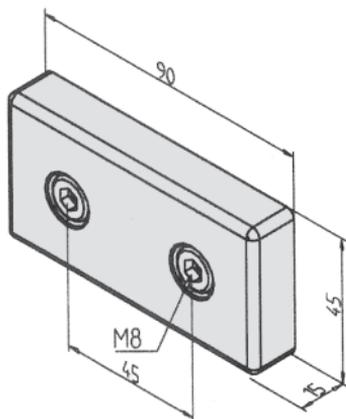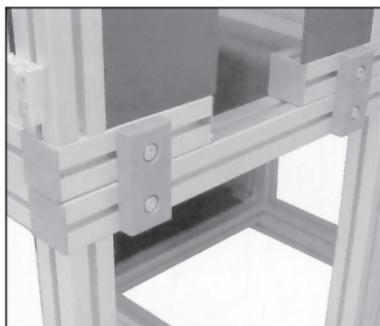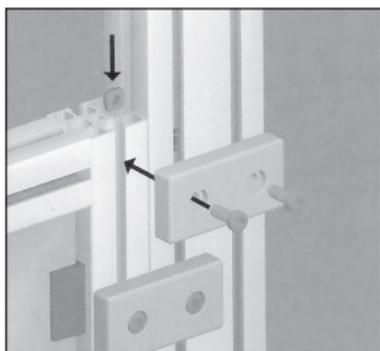

### DISCOUNTS

| Qty        | 1+  | 50+ | 100+       |
|------------|-----|-----|------------|
| Disc. List | -5% | -5% | On request |

| Part number | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|--------|--------------------|
| PRF-PL-4590 | 0,17        | ✓      | 10,10 €            |

\*Depending on availability - Dimensions in mm

**Stock**


# Joining plate for aluminium profile

## For joining pre-assembled **MiniTec** PRFPPL structures


- For joining two structures together
- Ensures rigid and stable installation of protective barriers
- Mounting kit supplied
- Material:  
Grey powder coated aluminium GD

### Assembly


- Use the fixing kit to attach to the mounting slot on the protective panel and the slot on the support profile

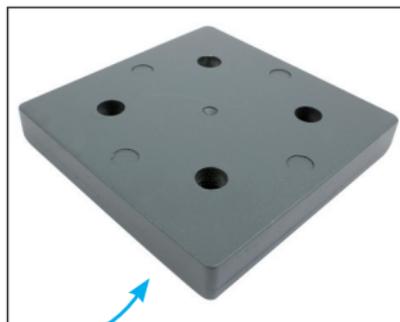

*Grey powder coated aluminium*

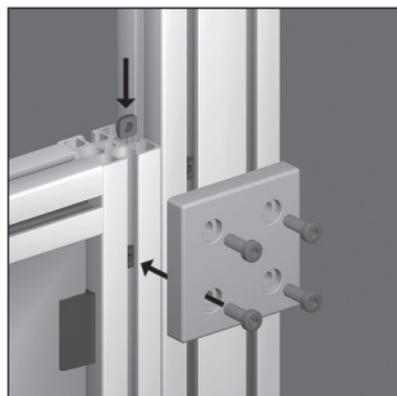

Typical assembly

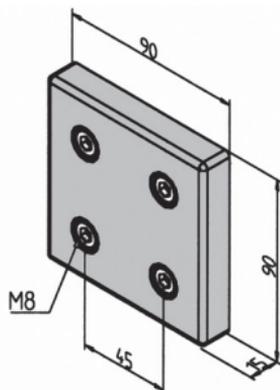

### DISCOUNTS

| Qty        | 1+ | 50+ | 100+       |
|------------|----|-----|------------|
| Disc. List |    | -5% | On request |

| Part number | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|--------|--------------------|
| PRF-PL-9090 | 0,33        | ✓      | 20,37 €            |

\*Depending on availability - Dimensions in mm

# Connection plate for aluminium profile

## ACLPL

## For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:  
Anodised aluminium

### Info.


 

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** (tome 1 p.562) and slot nut **PRF-ECL-M8/SS** (tome 5 p.315))





Typical application

Anodised aluminium

Aluminium profile

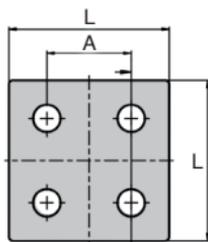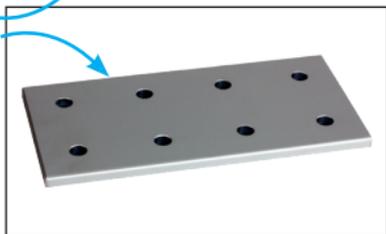

ACL-PL-9090

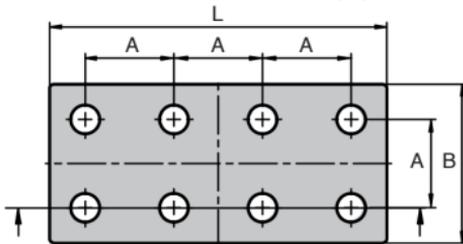 

ACL-PL-90180

### DISCOUNTS

|       |     |     |            |
|-------|-----|-----|------------|
| Qty   | 1+  | 50+ | 100+       |
| Disc. | Net | -5% | On request |

| Part number        | L   | B  | H | A  | ØD | Weight (g) | Price each 1 to 49 |
|--------------------|-----|----|---|----|----|------------|--------------------|
| <b>Square</b>      |     |    |   |    |    |            |                    |
| ACL-PL-9090        | 86  | -  | 6 | 45 | 9  | 115        | 9,46 €             |
| <b>Rectangular</b> |     |    |   |    |    |            |                    |
| ACL-PL-90180       | 176 | 86 | 6 | 45 | 9  | 240        | 16,13 €            |

All dimensions in mm

# Connection plate for aluminium profile



## Right angled connection

## ACLPR



- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:  
Anodised aluminium

### Info.

- Supplied without fixing kit (see button head screw BHC8-16/SS/B or BHC8-20/SS (tome 1 p.562) and slot nut PRF-ECL-M8/SS) (tome 5 p.315)

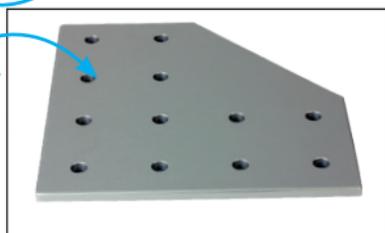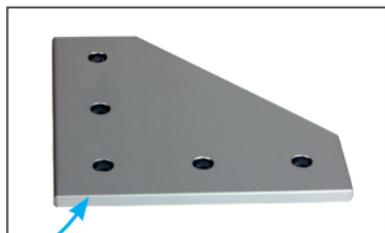

Typical application

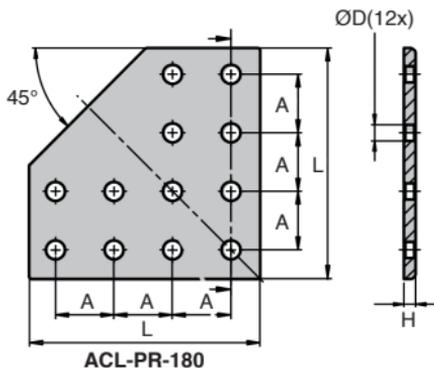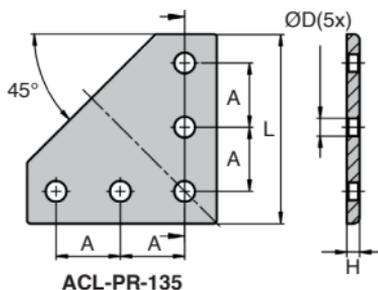

### DISCOUNTS

|           |     |            |      |
|-----------|-----|------------|------|
| Qty       | 1+  | 50+        | 100+ |
| Disc. Net | -5% | On request |      |

| Part number | L   | H | A  | ØD | Weight (g) | Stock* | Price each 1 to 49 |
|-------------|-----|---|----|----|------------|--------|--------------------|
| ACL-PR-135  | 133 | 6 | 45 | 9  | 215        | ✓      | 19,47 €            |
| ACL-PR-180  | 178 | 6 | 45 | 9  | 435        | -      | 30,20 €            |

\* Depending on availability - Dimensions in mm

# Connection plate for aluminium profile

## ACLPL


## Angle connection

- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:  
Anodised aluminium



### Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** (tome 1 p.562) and slot nut **PRF-ECL-M8/SS** (tome 5 p.315))

Anodised aluminium

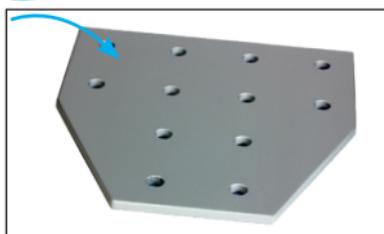

Typical application

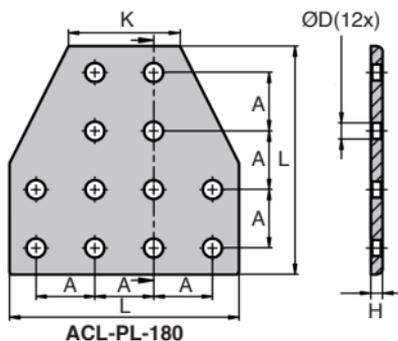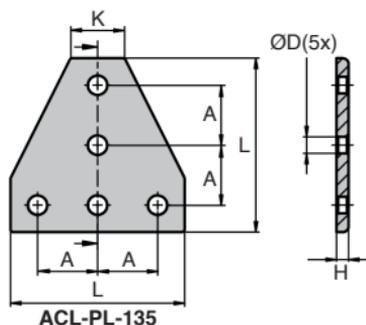

### DISCOUNTS

|           |     |            |      |
|-----------|-----|------------|------|
| Qty       | 1+  | 50+        | 100+ |
| Disc. Net | -5% | On request |      |

| Part number | L   | H | A  | K  | ØD | Weight (g) | Price each |
|-------------|-----|---|----|----|----|------------|------------|
|             |     |   |    |    |    |            | 1 to 49    |
| ACL-PL-135  | 131 | 6 | 45 | 41 | 9  | 210        | 20,80 €    |
| ACL-PL-180  | 176 | 6 | 45 | 86 | 9  | 425        | 34,18 €    |

All dimensions in mm

# Stock Adjustable plate for aluminium profile

## MiniTec PRFPA



- Supplied with fixing kit
- Material:  
covered steel

### Applications


- Attaches support bases to the conveyor of a chassis
- Can also be used with slope conveyors
- Range +/- 35°

### Assembly

- Attach to the side of the conveyor chassis and to the bases using the fixing kit

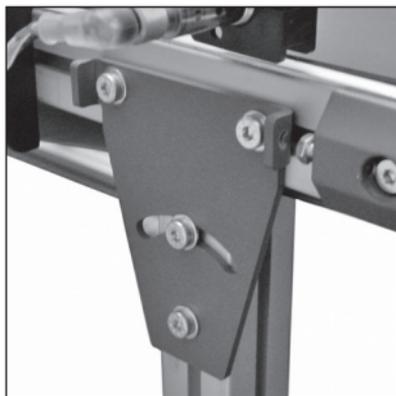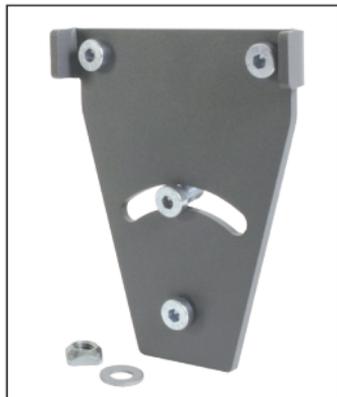

Typical application

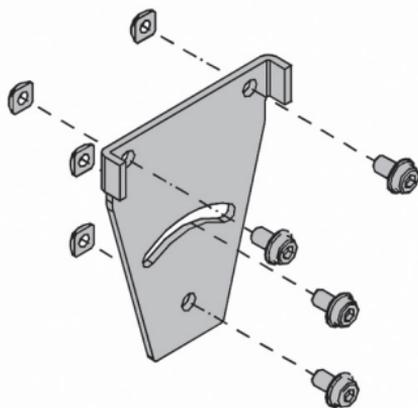

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Type        | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|-------------|--------|--------------------|
| PRF-PA      | Angle plate | 0,377       | ✓      | 30,90 €            |

\*Depending on availability - Dimensions in mm

# Adjustable joints for aluminium profiles

## ACLEAV ACLPAV

## Turning and pivot angle

- Components for creating angled joints

- Material

Turning angle : Cast aluminium

Pivot angle : chromed steel

### Advantages

- Adjustable angle

### Info

- No mounting screws supplied








(see PRF-ECL-M8/ screw FHC8 and CHC8)




ACL-EAV-45



ACL-PAV-130

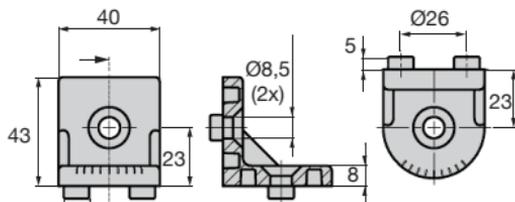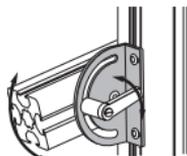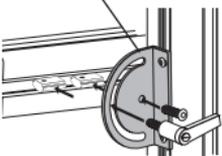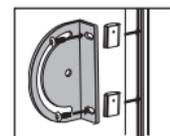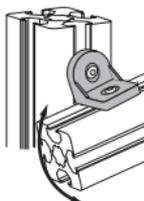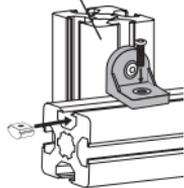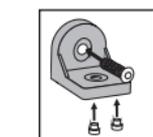

ACL-EAV-45

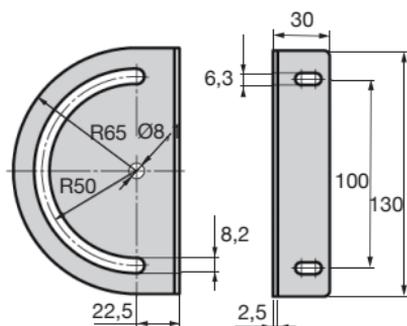

ACL-PAV-130

### DISCOUNTS

|            |     |            |      |
|------------|-----|------------|------|
| Qty        | 1+  | 50+        | 100+ |
| Disc. List | -5% | On request |      |

| Part number | Type          | Screw size | N    | Weight (g) | Stock* | Price each 1 to 49 |
|-------------|---------------|------------|------|------------|--------|--------------------|
| ACL-EAV-45  | Turning angle | M8         | 8/10 | 44         | ✓      | 5.03 €             |
| ACL-PAV-130 | Pivot angle   | M8         | -    | 221        | ✓      | 10.02 €            |

\*Depending on availability - Dimensions in mm

# Cross connector for aluminium profile

## MiniTec PRFRTR




- Allow profiles to be added to existing structures

- Material:

Chromed galvanised steel with pre-mounted  
M6 x 16 set screw

### Assembly

- Insert the connector into the existing frame.
- Slide the new profile on to the connector
- Tighten the set screw with a 3mm key to a torque of 10Nm

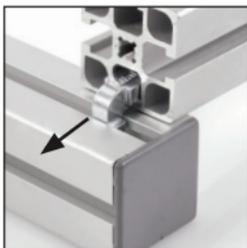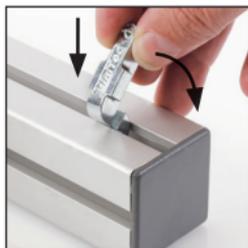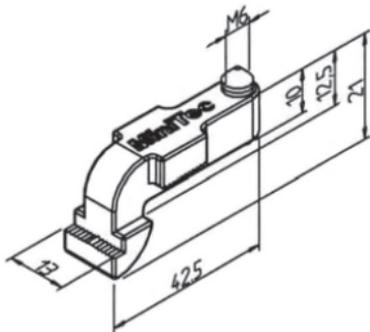

Typical assembly

### DISCOUNTS

| Qty   | 1+   | 50+ | 100+       |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|--------|--------------------|
| PRF-RTR     | 0.04        | -      | 10.06 €            |

\*Depending on availability - Dimensions in mm

# Coupling bar for aluminium profile Stock

## PRFRR **MiniTec**



- Supplied with fixing kit
- Material:  
electroplated steel

### Advantages


- Allows profiles of different sections to be joined together
- Can also be used to add additional profiles

### Assembly

- Attach the bar to the slot with the fixing kit
- No preparation necessary

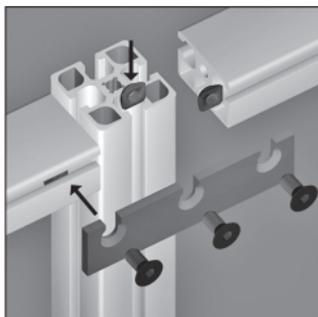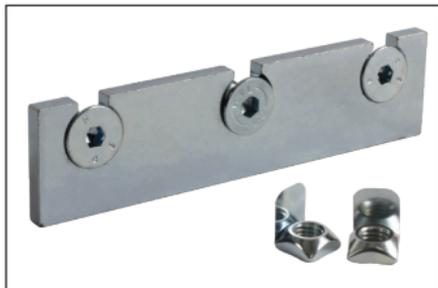

Typical assembly

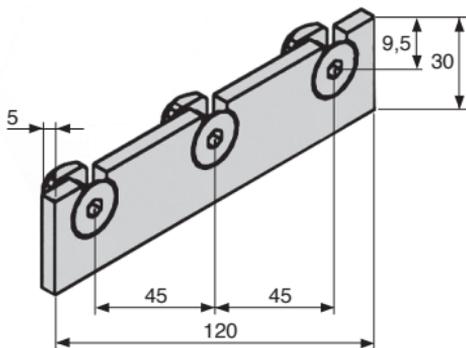

### DISCOUNTS

| Qty   | 1+   | 50+ | 100+       |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | Type         | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|--------------|-------------|--------|--------------------|
| PRF-RR-120  | Coupling bar | 0,103       | ✓      | 15,10 €            |

\*Depending on availability - Dimensions in mm



- Supplied with fixing kit
- Material:  
Anodised aluminium

### Use


- Use the slots on two profiles to connect them at any angle

### Assembly

- Attach the clamp to the slot of the first profile and then tighten the second and then tighten the second
- No preparation required

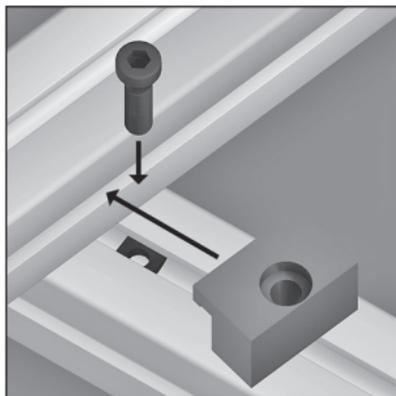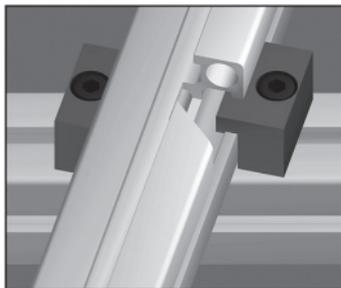

Mounting example

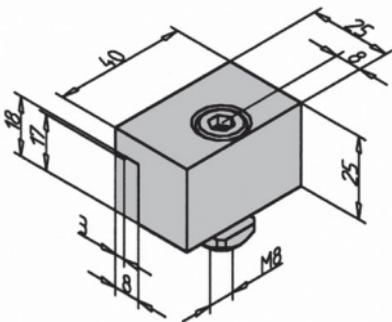

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Type  | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------|-------------|--------|--------------------|
| PRF-BR      | Clamp | 0,069       | ✓      | 14,12 €            |

\*Depending on availability - Dimensions in mm

# Bracket for aluminium profiles

Stock

PRF<sub>E</sub> **MiniTec**

Support bracket

- **Assembling profiles**
- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- Material: grey powder coated aluminium GD



## Accessories



- Nut with sprung tab **PRF-ECL**

## Special application


- **PRF25-E** bracket has a centering grooves

## Info.


- \*Given for applications using two brackets; when using a single bracket, maximum load is reduced, please contact us for details

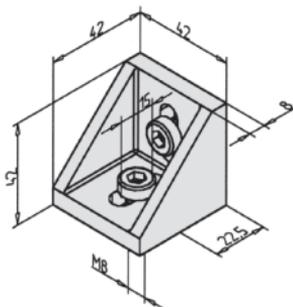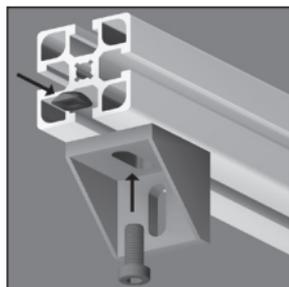

PRF45-E

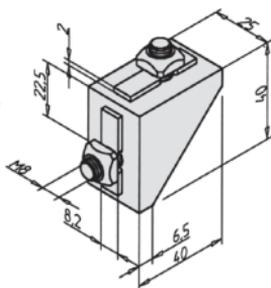

PRF25-E

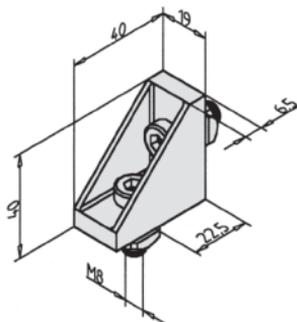

PRF19-E

## DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Max. load* (N) | Max. torque (Nm) | For profile         | Tightening torque (Nm) | Stock* | Price each 1 to 49 |
|-------------|----------------|------------------|---------------------|------------------------|--------|--------------------|
| PRF19-E     | 1200           | 400              | PRF19, PRF32        | 20                     | ✓      | 5,85 €             |
| PRF25-E     | 1200           | 400              | PRF19, PRF32, PRF45 | 20                     | ✓      | 6,35 €             |
| PRF45-E     | 1200           | 400              | PRF45               | 20                     | ✓      | 5,52 €             |

\*Depending on availability - Dimensions in mm

- **Assembling profiles**
- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- **PRF90-E** supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm




### Accessory


- Nut with sprung tab **PRF-ECL**

### Info.


- \*For applications using two brackets, or when using a single bracket maximum load is reduced

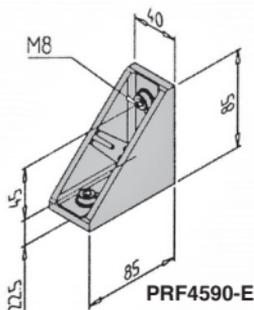

PRF4590-E

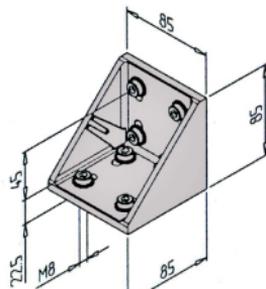

PRF90-E

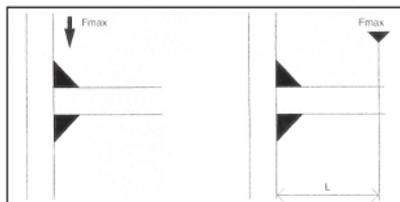

Maximum load and torque

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Max. load* (N) | Max. torque (Nm) | For profile | Tightening torque (Nm) | Stock* | Price each 1 to 49 |
|-------------|----------------|------------------|-------------|------------------------|--------|--------------------|
| PRF4590-E   | 2400           | 800              | PRF4590     | 20                     | ✓      | 12,32 €            |
| PRF90-E     | 4800           | 1600             | PRF4590     | 20                     | ✓      | 28,80 €            |

\*Depending on availability - Dimensions in mm

# Right angled bracket for aluminium profiles

## ACLEPP Bracket for connecting 2 profiles

- To join 2 profiles at 90°
- Material  
Anodised aluminium  
For use with single slot profiles

### Advantages

- Suitable for use with PRF aluminium profiles

### Info


- No mounting screws supplied





ACL-EPP2-4545




ACL-EPP4-4590

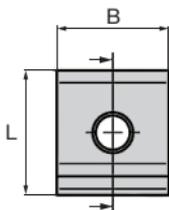

ACL-EPP2- 4545

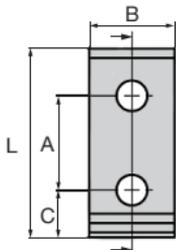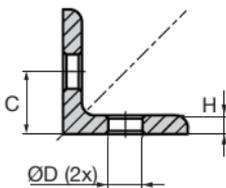

ACL-EPP4-4590

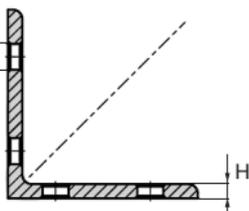

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number   | Version | L  | B  | H | A  | C    | ØD | Weight (g) | Stock* | Price each 1 to 49 |
|---------------|---------|----|----|---|----|------|----|------------|--------|--------------------|
| ACL-EPP2-4545 | 2 holes | 45 | 41 | 6 | -  | 22,5 | 9  | 55         | ✓      | 3,56 €             |
| ACL-EPP4-4590 | 4 holes | 90 | 41 | 6 | 45 | 22,5 | 9  | 112        | ✓      | 7,11 €             |

\* Depending on availability - Dimensions in mm



# Right angled bracket for aluminium profiles

## Bracket for connecting 2 profiles

## ACLEPP

- To join 2 profiles at 90°
- Material  
Anodised aluminium  
For use with dual slot profilest

### Advantages

- Suitable for use with PRF4590 aluminium profiles

### Info



- No mounting screws supplied





ACL-EPP4-9045



ACL-EPP8-9090

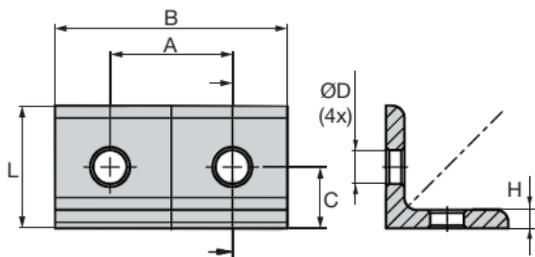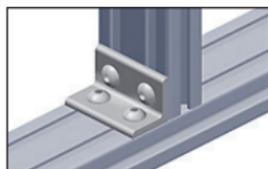

ACL-EPP4-9045

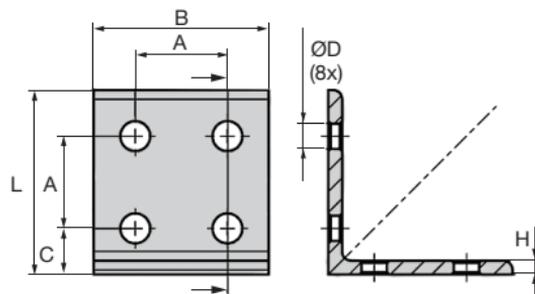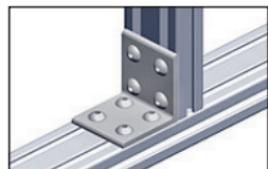

ACL-EPP8-9090

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number   | Version | L  | B  | H | A  | C    | ØD | Weight (g) | Stock* | Price each 1 to 49 |
|---------------|---------|----|----|---|----|------|----|------------|--------|--------------------|
| ACL-EPP4-9045 | 4 holes | 45 | 86 | 6 | 45 | 22,5 | 9  | 112        | ✓      | 7,86 €             |
| ACL-EPP8-9090 | 8 holes | 90 | 86 | 6 | 45 | 22,5 | 9  | 235        | ✓      | 13,20 €            |

\* Depending on availability - Dimensions in mm

# Corner reinforcement

Stock

## PRFT **MiniTec**

- Supplied with fixing kit

- Material:



Anodised aluminium

### Uses


- For reinforcing structures
- Used for attaching feet to the inside of a chassis
- Also used for levelling or anchoring structures to the floor

### Assembly

- Mounts on the side of a profile using the fixing kit supplied
- Used with anchoring kit to attach a structure to the floor.

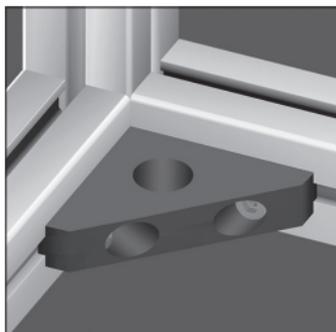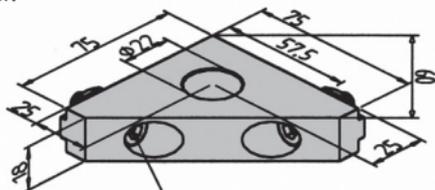

Used as reinforcement

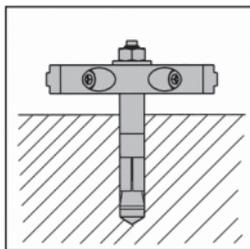

Used for reinforcing and anchoring

### DISCOUNTS

|            |     |            |      |
|------------|-----|------------|------|
| Qty        | 1+  | 50+        | 100+ |
| Disc. List | -5% | On request |      |

| Part number | Type   | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|--------|-------------|--------|--------------------|
| PRF-T-75    | Corner | 0,17        | ✓      | 29,88 €            |

\*Depending on availability - Dimensions in mm


- Base plate for attaching levelling foot or lifting ring
- Fixing kit supplied
- Foot ring not supplied
- Material: grey powder covered steel

### Assembly


- Fits in slot on profile

### Accessories

- Feet (tome 1 p.368)

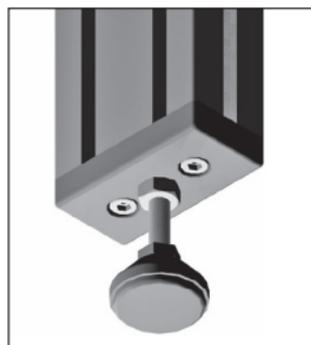

Typical application

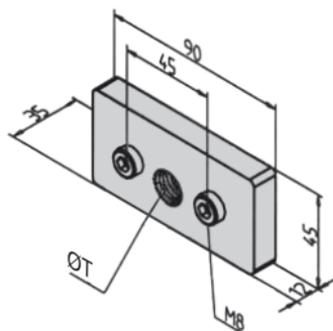

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number  | ØT<br>Thread | For<br>profile | Thickness<br>(mm) | Weight<br>(kg) | Stock* | Price each<br>1 to 49 |
|--------------|--------------|----------------|-------------------|----------------|--------|-----------------------|
| PRF4590-BM10 | M10          | PRF4590        | 15                | 0,164          | -      | 14,62 €               |
| PRF4590-BM12 | M12          | PRF4590        | 15                | 0,162          | -      | 14,62 €               |
| PRF4590-BM16 | M16          | PRF4590        | 15                | 0,160          | -      | 16,23 €               |
| PRF4590-BM20 | M20          | PRF4590        | 15                | 0,156          | -      | 13,08 €               |

\*Depending on availability - Dimensions in mm



**MINIMUM  
ORDER  
20€\***



**VOLUME  
DISCOUNT**

**1,2,3  
PRODUCTS  
SOLD  
INDIVIDUALLY**



**CAD FILES  
STEP, IGES...**



**MADE TO  
MEASURE  
AVAILABLE**



**CAD FILES  
STEP, IGES...**

**1,2,3  
PRODUCTS  
SOLD  
INDIVIDUALLY**



**FREE  
CATALOGUES**



**VOLUME  
DISCOUNT**



**MADE TO  
MEASURE  
AVAILABLE**

**FREE**

**DELIVREY**

**FOR ORDERS**

**100€\* OR MORE**



**CAD FILES  
STEP, IGES...**

**1,2,3  
PRODUCTS  
SOLD  
INDIVIDUALLY**



**FAST  
QUOTES  
& ORDERS**



**VOLUME  
DISCOUNT**

\* Certain conditions apply - Deliveries to mainland France only

- Supplied without fixing kit
- Material: grey powder covered steel

### Uses


- Used to anchor a structure to a floor or wall

### Assembly

- Attaches to profile using M8 x 20mm screws.
- Attaches to floor or wall using anchoring system
- Can be added to existing structures



Typical application

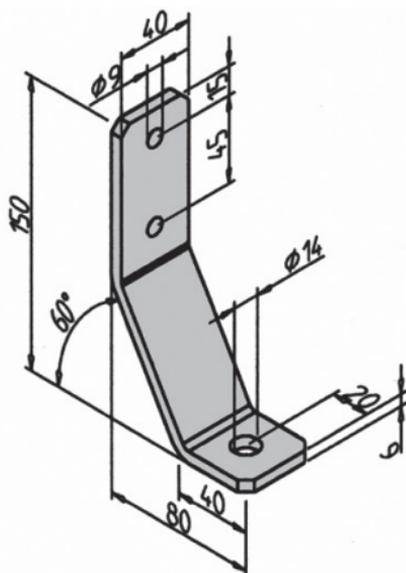

### DISCOUNTS

| Qty   | 1+   | 50+ | 100+       |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | Type           | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|----------------|-------------|--------|--------------------|
| PRF-PF-150  | Anchor bracket | 0,355       | ✓      | 19,79 €            |

\*Depending on availability - Dimensions in mm

# Floor anchor for aluminium profiles

## ACLEFS



## Right angled floor anchor

- For securing aluminium profiles to a floor

- Material :  
Die cast zinc

### Advantages

- Suitable for use with PRF aluminium profiles
- Only for use with profiles wider than 40mm

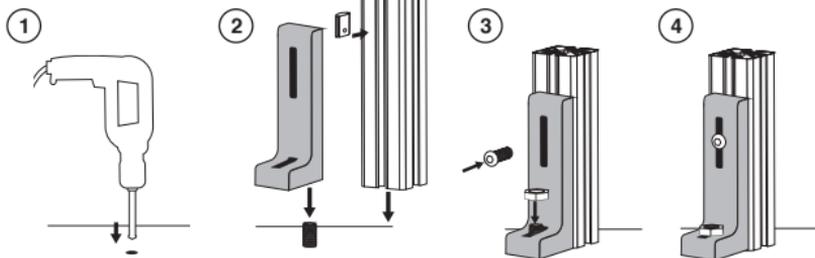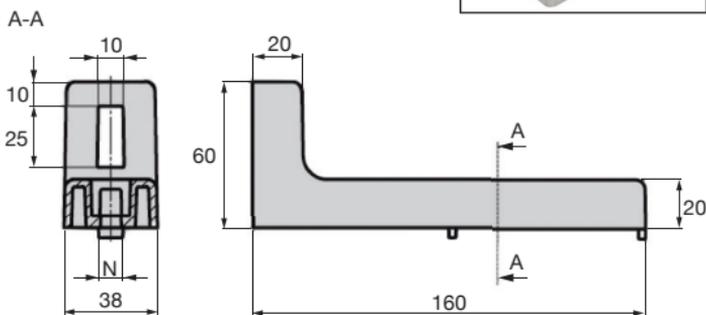

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | N | Weight (g) | Stock* | Price each 1 to 49 |
|-------------|---|------------|--------|--------------------|
| ACL-EFS-160 | 8 | 110        | ✓      | 15,14 €            |

\* Depending on availability - Dimensions in mm



# Floor anchor for aluminium profiles

## Adjustable height floor anchor

## ACLEFS/A

- For securing aluminium profiles to a floor



Material:

Die cast zinc

### Advantages

- Adjustable
- Suitable for use with PRF aluminium profiles

Adjustable

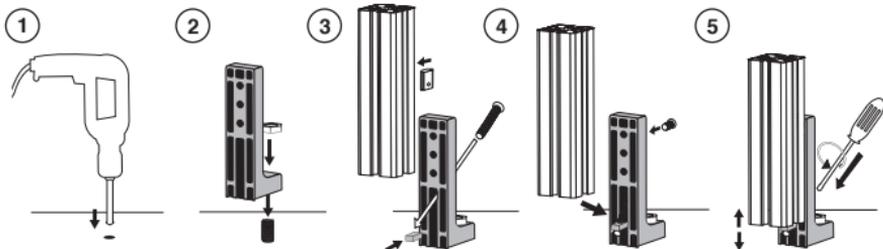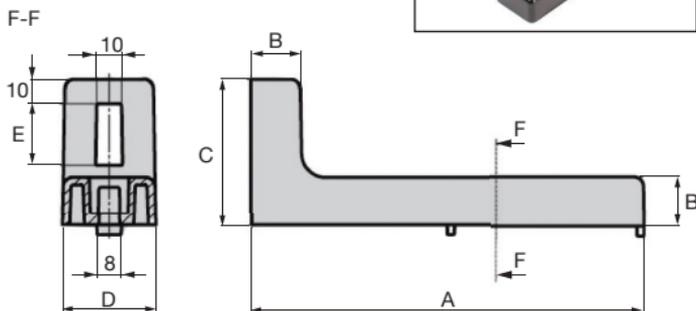

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number   | Profile size (mm) | A   | B  | C  | D  | E  | Max height | Weight (g) | Stock* | Price each 1 to 49 |
|---------------|-------------------|-----|----|----|----|----|------------|------------|--------|--------------------|
| ACL-EFS-120/A | 30 min            | 120 | 15 | 45 | 28 | 19 | 52         | 88         | ✓      | 16,00 €            |
| ACL-EFS-160/A | 40 min            | 160 | 20 | 60 | 38 | 29 | 72         | 120        | ✓      | 23,68 €            |

\* Depending on availability - Dimensions in mm

# Foot support for aluminium profile

## PRFP

## Very stable


- Allows feet or casters to be added to a structure
- Supplied with mounting kit
- Material:  
Aluminium GD, grey painted protective (shore) finish

### Applications


- Mounting of feet or casters

### Assembly

- Mounts directly on the aluminium profile using the screws supplied
- Mount swivelling M10 foot or a caster with M10 thread.

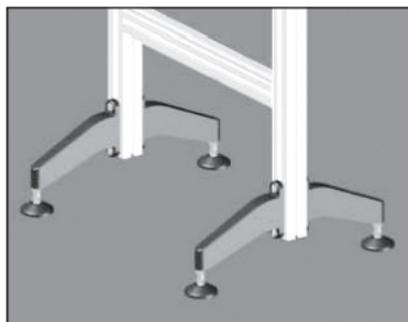

Typical application

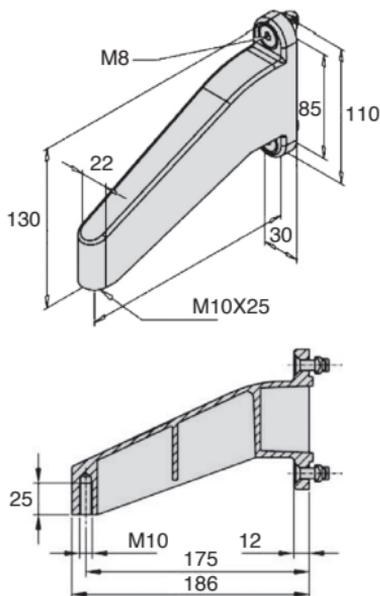

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Type         | Weight (kg) | Price each         |
|-------------|--------------|-------------|--------------------|
| PRF-P-175   | Foot support | 0,368       | 1 to 49<br>24,95 € |

Dimensions in mm

- Supplied with profile fixing kit
- Material: grey powder covered steel

### Uses


- For attaching panels or chassis to floors
- Suitable for all profiles up to 45x45mm

### Assembly


- Insert the profile into the foot
- Insert nuts with sprung tabs into the slots on the profile and lightly tighten the screws
- Make final adjustments to the position of the profile and then firmly tighten the screws
- Use anchoring system if fixing to a floor



Typical application

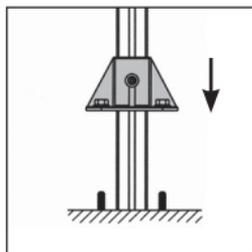

Mounting example

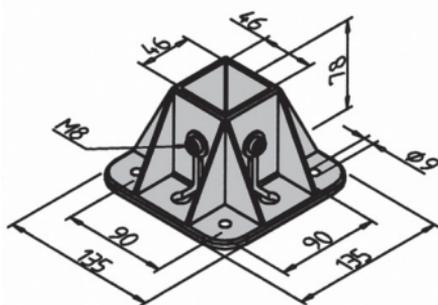

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Type   | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|--------|-------------|--------|--------------------|
| PRF-P-45    | Anchor | 0,595       | ✓      | 33,29 €            |

\*Depending on availability - Dimensions in mm