

Caster for use with aluminium profile

PRFROUL **MiniTec**

With brake

- Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

Uses

- Light mobile tables

- Wheeled filing cabinets


- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

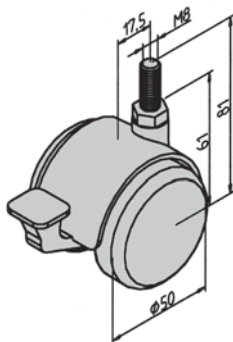

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL/F	Caster with brake	0,08	✓	10,45 €

*Depending on availability - Dimensions in mm

Caster for use with aluminium profile

Without brake

MiniTecPRFROUL

- Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

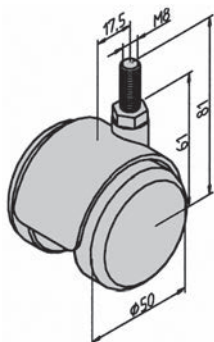


DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL	Castor without brake	0,076	✓	8,48 €

*Depending on availability - Dimensions in mm

 Our other products



GPLso

Brush, silk



ADL_M

Male eye bolt
conforms to DIN580,
Stainless steel



SSDB

Stainless steel bevel
gear, 2:1



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



WSS

Symmetrical S shaped
hook, Steel



JSM

Cylindrical polymer
bush, Universal
polymer



LVT

Miniature motorised
actuator 4A, 4 ampers



CLASS

Stainless steel
indexing handle -
female, Stainless steel



GE1006

Elastic ringed latch,
Hooks into a slot



PDR-RD

Mounting feet with
integrated castors,
Offset castor



DBL820

Idler for slat top
chain, Ranges 820
and 815



NRV

Orthogonal support
clamp, Orthogonal
support clamp

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm