

# Caster for use with aluminium profile

## PRFROUL **MiniTec**

### With brake

#### - Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

#### Uses

- Light mobile tables

- Wheeled filing cabinets


- Furniture

#### Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

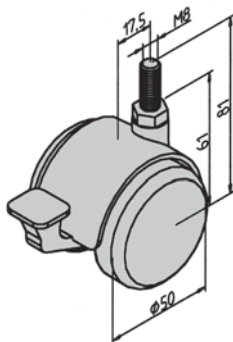

#### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL/F	Caster with brake	0,08	✓	10,45 €

\*Depending on availability - Dimensions in mm

# Caster for use with aluminium profile

Without brake

**MiniTec**PRFROUL

## - Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

## Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

## Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

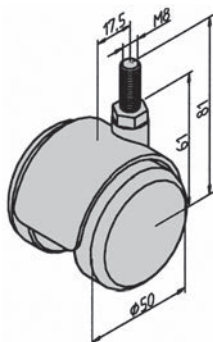

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL	Castor without brake	0,076	✓	8,48 €

\*Depending on availability - Dimensions in mm

## Our other products



PP35

Worm and wheel gear reducer, from 2.20 to 4.10 Nm



NCT

Square tube connector, Fixed angle



CHAuss

Screwed hinge, 270°



E40

Right angle helical reducers, from 2.30 to 20 Nm



HRV

V- rail guidance Simple Select® system, Rail with carriage



KKB-AR

Linear bearing with inclined ball tracks, Standard loads / -20° +20...



LVT

Miniature motorised actuator 4A, 4 amperers




DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



GG2

 Ground spur gear, Heat treated steel



GPLso

Brush, silk



SHW

Plain washer, A2 Stainless steel



CAP805

Slat top chain stainless steel, Large range 805

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm