

Caster for use with aluminium profile

PRFROUL **MiniTec**

With brake

- Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

Uses

- Light mobile tables

- Wheeled filing cabinets


- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

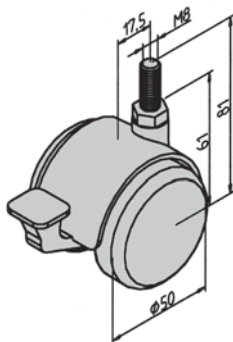

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL/F	Caster with brake	0,08	✓	10,45 €

 
*Depending on availability - Dimensions in mm

Our other products



MRASSeco

Low cost stainless steel quick link, Stainless steel



M1

Worm and wheel set, Machined plastic (delrin)



WS10

Drylin® W rail, Rail



SC2

2 part rigid shaft clamp, Clamping jaw



CHAL3

Piano hinge, Steel




PF55

Worm and wheel gear reducer, up to 57 Nm




CLASS

 Stainless steel indexing handle - female, Stainless steel



GLT3-76

 Telescopic drawer,



GMC

Flat profile - Round guide, Flat profile -



H0

Crossed helical gear crossed axis at 90°,



ACL-PL

Joining plate for aluminium profile,



CLB_M

Die cast zinc clamping lever - female, Zamak

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm