

# Caster for use with aluminium profile

## PRFROUL **MiniTec**

### With brake

#### - Materials:

Casing : black polyamide

Double wheel: black polyamide

- Max. load: 30kg

#### Uses

- Light mobile tables

- Wheeled filing cabinets


- Furniture

#### Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

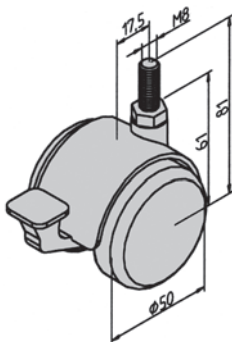

#### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-ROUL/F	Caster with brake	0,08	✓	10,45 €

\*Depending on availability - Dimensions in mm

## Our other products



MRAeco  
Low cost quick link,  
Steel



PM4  
Worm and wheel set,  
Machined plastic  
(delrin)



DOMI120  
Accessories, Fixing kit



PFC  
Fixed rubber levelling  
foot, Levelling support  
for small parts



PR821  
Idler sprocket for slat  
top chain, Ranges 821  
and 805



BABFCFO  
Ball pin socket,  
Mounting collar with a  
round flange




PO  
Pull handle - Multi-  
sector, Tapped  
recessed insert




GD01  
Double universal joint,  
Standard duty



 HTD8M-BAR  
HTD type tooth bar  
stock, HTD8



 RPPM  
RPP type belt per  
metre, RPP8 Steel



IN1  
Internal gear,  
Machined plastic



RTN  
BoWex® curved tooth  
gear coupling, Nylon

## Complementary products



PRF4545  
Standard aluminium  
profile, 45 x 45 mm