

Support for Ø12mm Prox detector

Stock

PRF_{SDD} **MiniTec**

Suitable for use with aluminium profiles


- Suitable for all Ø12mm proximity detectors
- Fixing kit supplied
- Material: black plastic

Use


- Allows a Ø12mm proximity detector to be mounted on a profile or linear guide

Assembly

- Mounts in the slot of a profile using the fixing kit supplied.

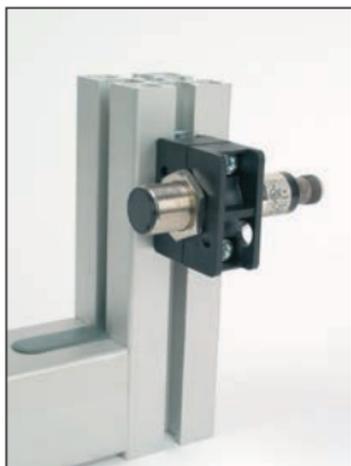

Typical application

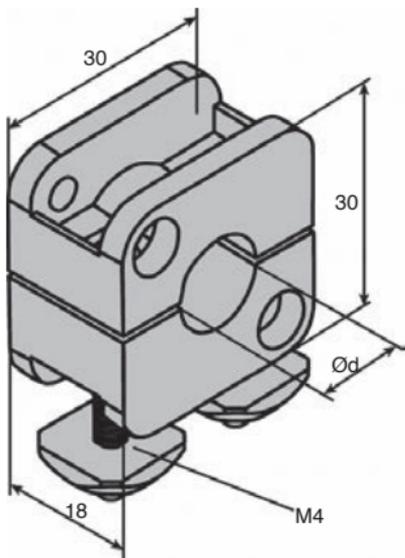

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Ød	Weight (g)	Stock*	Price each 1 to 49
PRF-SDD-12	12	40	✓	4.91 €

*Depending on availability - Dimensions in mm

Stock Support for Ø18 or Ø20mm Prox detectors

Suitable for use with aluminium profiles

MiniTec PRFsDD

- Suitable for all Ø18 or Ø20mm proximity detectors
- Fixing kit supplied
- Material: black plastic

Use


- Allows an Ø18 or Ø20mm proximity detector to be mounted on a profile or linear guide

Assembly

- Mounts in the slot of a profile using the fixing kit supplied



Typical application

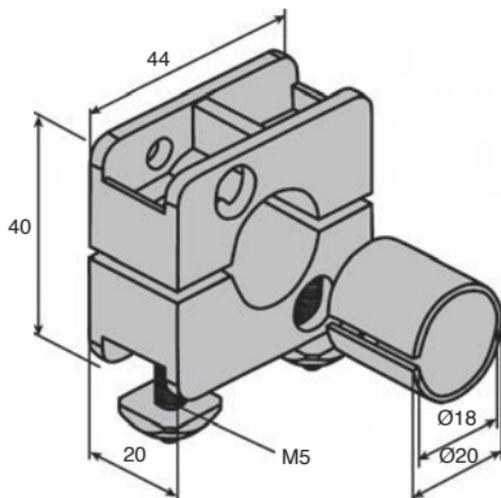

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number

PRF-SDD-18/20

Weight (g)

50

Stock*

✓

Price each
1 to 49

5,99 €

*Depending on availability - Dimensions in mm

Our other products



F7-P-AM

Multifunction display,
Magnetic ring



CHAK

Hi-Klik™ indent
hinge, Hi-Klik™ -
Detent hinge



PSG05

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



BOX-TOR-A

Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 28.17 x
3.53



PSG05

Spur gear - precision
range, Case hardened
steel 20NCD2



APB_F

Adjusting rod for
clamp - Male,
Threaded



PR85

Articulated foot Ø83,
Ø 83



HW_HT

Half-rail guide, Wheel



MEB

Moulded plastic bevel
gear (nylon), 1:1



EX

Optional shaft for E-
type gear reducers, E



RPCtcss

Swivel castor with
central hole, Stainless



STL

Guidance brush - Rail,
Rail

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm