

Support for Ø12mm Prox detector



PRF_{SDD} **MiniTec**

Suitable for use with
aluminium profiles

- Suitable for all Ø12mm proximity detectors
- Fixing kit supplied
- Material: black plastic

Use


- Allows a Ø12mm proximity detector to be mounted on a profile or linear guide

Assembly

- Mounts in the slot of a profile using the fixing kit supplied.



Typical application

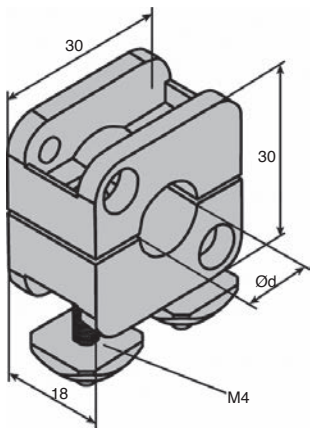

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Ød	Weight (g)	Stock*	Price each 1 to 49
PRF-SDD-12	12	40	✓	4,91 €

*Depending on availability - Dimensions in mm

Stock Support for Ø18 or Ø20mm Prox detectors

Suitable for use with
aluminium profiles

MiniTec PRFSDD


- Suitable for all Ø18 or Ø20mm proximity detectors
- Fixing kit supplied
- Material: black plastic

Use


- Allows an Ø18 or Ø20mm proximity detector to be mounted on a profile or linear guide

Assembly

- Mounts in the slot of a profile using the fixing kit supplied

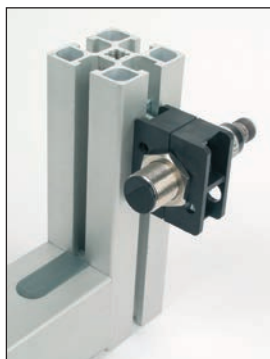

Typical application

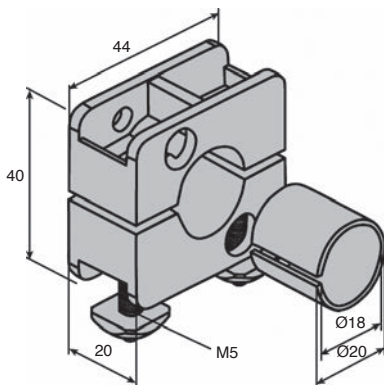

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (g)	Stock*	Price each 1 to 49
PRF-SDD-18/20	50	✓	5,99 €

*Depending on availability - Dimensions in mm

Our other products



BWU
Compact precision
slide, from 1510 N to
10500 N



HTD14M_55
HTD Heavy duty
timing pulley, HTD14
Steel



E50
Right angle helical
reducers, from 3 to 41
Nm



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



ZBconique
Machined plastic
bevel gear , 1:1



PP50
Worm and wheel gear
reducer, from 6.50 to
12.80 Nm



CHA35
Hinge for aluminium
profile, Hinge



APB_F
Adjusting rod for
clamp - Male,
Threaded



TB8
Cylindrical roller
thrust bearing, Steel



RURp
Fixed castor with
plate, Polyurethane -
Aluminium rim (Free



BABpss
301 Stainless steel
ball pin, Stainless
steel



PTA40
Articulated foot with
solid base foot Ø 40,
3000N

Complementary products



PRF4545
Standard aluminium
profile, 45 x 45 mm