

- Supplied with fixing kit

- Material:



Anodised aluminium

Uses


- For reinforcing structures or assemblies
- Used for attaching feet to the inside of a chassis
- Also used for levelling or anchoring structures to the floor

Assembly

- Mounts on the side of a profile using the fixing kit supplied
- Used with anchoring kit to attach a structure to the floor.

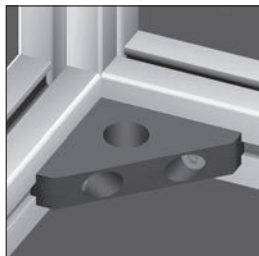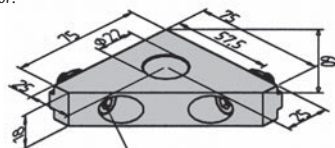

Used as reinforcement

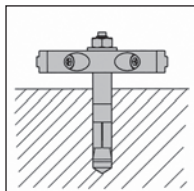

Used for reinforcing and anchoring

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-T-75	Corner	0,17	✓	30,20 €

*Depending on availability - Dimensions in mm

Our other products



RPCpl
Fixed castor with
plate, Steel -
Polyamide



MCLred
Reducing sleeve
female/female,
Cylindrical - steel



PW_PWG15
Worm - precision
range, Stainless steel



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880



DTR
Chain idler sprocket,
Chain idler sprocket -
Steel




T5-16ECO
T type timing pulley,
Economy range - T5
aluminium



PSG05
Spur gear - precision
range, Case hardened
steel 20NCD2



 V3RA_PT
3-spoked handwheel
with handle,
Polyamide



RPPM
RPP type belt per
metre, RPP8 Steel



GTC
Belt tensioner, For
standard applications



PCLA_M
Technopolymer
clamping lever -



CHT
Asynchronous AC
motor, 0.09kW

Complementary products



PRF4545
Standard aluminium
profile, 45 x 45 mm