


Assembly key

- Materials:
 Shaft: chromed steel
 Handle: black plastic

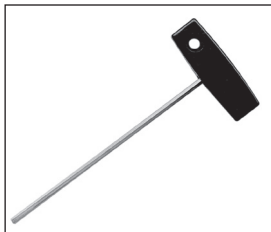

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%		On request

Part number	Type	SW	Weight (kg)	Stock*	Price each 1 to 4
PRF-TOOL-H4	Clef de montage	4	-	✓	13,47 €
PRF-TOOL-H5	Clef de montage	5	-	✓	13,82 €

*Depending on availability - Dimensions in mm

Our other products



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - steel



MSP3815

Masterplate® glueable insert rectangular, rectangular with nut



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast



PLM-SC

Magnetic stud with central countersunk hole, With milled bore



VELM4

Screw-on base for hook-and-loop strip, Polyamide



NCT

Square tube connector, Fixed angle



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



CCLSS

Stainless steel wire thimble, Stainless steel



UGH20

H Type Guide units, For Ø20 actuators



PGM52-M4

Pull handle, Brass



R205

Die spring ISO10243, Heavy



GLP

Small 6 lobe threaded handle - male, Technopolymer - Steel

Complementary products



PRF4545_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm