

Bracket for aluminium profiles

Stock

PRF **MiniTec**

Support bracket

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- Material: grey powder coated aluminium GD

Accessories



- Nut with sprung tab PRF-ECL

Special application


- PRF25-E bracket has a centred section that aligns along profile slot to prevent twisting

Info.


- *Given for applications using two brackets; when using a single bracket, maximum load is reduced, please contact us for details

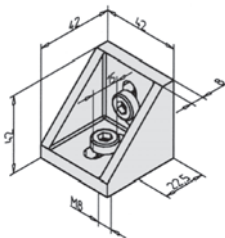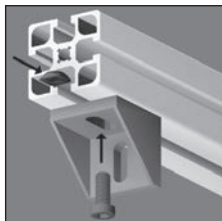

PRF45-E

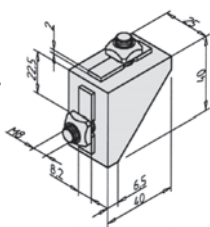

PRF25-E

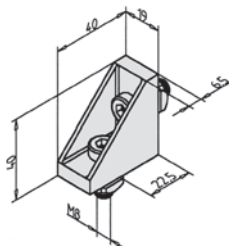

PRF19-E

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF19-E	1200	400	PRF19, PRF32	20	✓	4,27 €
PRF25-E	1200	400	PRF19, PRF32, PRF45	20	✓	4,91 €
PRF45-E	1200	400	PRF45	20	✓	4,27 €

*Depending on availability - Dimensions in mm

Our other products



HBM
Adjustment bushing for half-rail guide,
Adjustment bushing



PSG125
Spur gear - precision range, Case hardened steel 20NCD2



HBM
Adjustment bushing for half-rail guide,
Adjustment bushing



LC
Friction clutch, 30 to 240 Nm



MSP38
Masterplate® glueable insert Ø38,
Cylindrical Ø38 with threaded s...



HDSS
Needle roller double universal joint -
Stainless steel, Heavy duty



BSM_LOK
Long-Lok spring plunger with internal hexagonal socket,
LONG-LOK - s...



LRM
Trapezoidal bronze nut, Bronze - 1 thread



SLBW
Indexing plunger, weldable, Weldable -
Steel



DSF
Slip friction clutch, 4 to 2600 Nm



RHTplss
High Temperature Castor, up to 200kg



DKN
Bellows coupling Gerwah®, from 0.4 to 10Nm

Complementary products



PRF_ECL
Nut for aluminium profile, Steel square nut with tab



PRF_VTM
Hammerhead screw, Hammerhead screw