

- Profile for creating modular structures
- To be cut to length once supplied
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

Accessories

- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

Uses


- Light supports
- Handles
- Detector and switch supports
- Frames




Typical application



Typical application

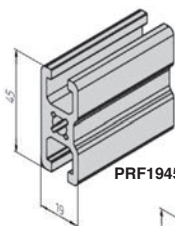

PRF1945-3

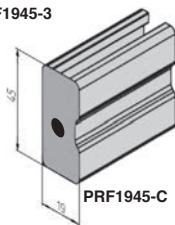

PRF1945-C

DISCOUNTS profile DISCOUNTS cover

Qty	1+	5+	10+	Qty	1+	50+	100+
Disc.	List	-5%	On request	Disc.	List	-5%	On request

Part number	lx (cm ²)	ly (cm ²)	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF1945-3	6,051	1,83	3000	1,087	✓	63,72 €
Cover						
PRF1945-C		End cover with pin			✓	1,04 €

*Depending on availability - Dimensions in mm

Our other products



ZG4

Plastic spur gear,
Machined plastic
(delrin)



 
CMM_SS

Male rod ends DIN
ISO12240-4, Stainless
steel / bronze -
Economy range



BEAB

Knob star grip
antibacterial, Star,
anti-bacterial



PX_PO

Carrying handle, back-
plated



PTR

Idler chain sprocket,
For standard
applications



BFD

Locking pin for bush,
+180°C



INStool

Insertion tool for self
tapping inserts,
Insertion tool



PR40

Articulated foot Ø40,
Ø 40




DOMI30

Connecting kits, XY
linking kit



CF

 Cam follower,
Standard - steel



R_RR

Narrow spur rack,
Steel



CHM75

Worm and wheel gear
reducer, up to 298
Nm

Complementary products



PRF_FIX_UNI

Universal fastener for
aluminium profile,
Universal



PRF19_E

Bracket for aluminium
profile, PRF19 to
PRF45