

- Profile for creating modular structures
- To be cut to length once supplied
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details



### Accessories

- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

### Uses


- Light supports
- Handles
- Detector and switch supports
- Frames




Typical application



Typical application

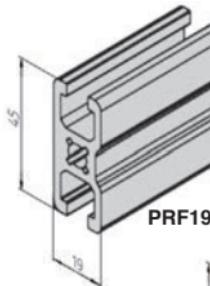

PRF1945-3

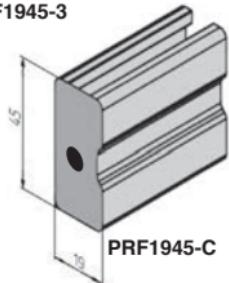

PRF1945-C

### DISCOUNTS profile DISCOUNTS cover

Qty	1+	5+	10+	Qty	1+	50+	100+
Disc.	List	-5%	On request	Disc.	List	-5%	On request

Part number	Ix (cm <sup>2</sup> )	Iy (cm <sup>2</sup> )	Length (mm)	Weight (kg/m)	Stock*	Price each
PRF1945-3	6,051	1,83	3000	1,087	✓	63,72 €
Cover					✓	1,04 €

\*Depending on availability - Dimensions in mm

## Our other products



ASL  
45° Hoist ring for welding, for 45° lifts - for welding



NPTR10  
Adjustable cross clamp, Adjustable



G0  
Steel spur gear, Steel 20NCD2



LRR-53  
Spring loaded latch, Spring return latch - steel



CHMR75  
Worm and wheel gear reducer, up to 298 Nm



DOG111  
Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



PRES2HR  
Manual workbench press, Force up to 200kg



PGMSS  
Stainless steel push/pull handle, Stainless steel



PTA80  
Articulated levelling foot, pressed base Ø80, 10000N



RPPM  
RPP type belt per metre, RPP14 Steel cored polyurethane



CHMX\_CHMDX  
Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHMX



BFDdII  
Locking pin for bushes, Nickel-plated steel

## Complementary products



PRF\_FIX\_UNI  
Universal fastener for aluminium profile, Universal



PRF19\_E  
Bracket for aluminium profile, PRF19 to PRF45