

- Profile for creating modular structures
- To be cut to length once supplied
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

Accessories

- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

Uses


- Light supports
- Handles
- Detector and switch supports
- Frames




Typical application



Typical application

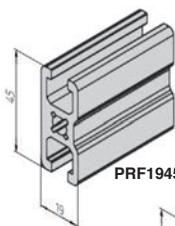

PRF1945-3

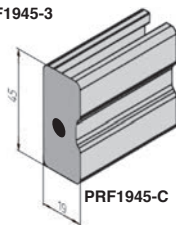

PRF1945-C

DISCOUNTS profile DISCOUNTS cover

Qty	1+	5+	10+	Qty	1+	50+	100+
Disc.	List	-5%	On request	Disc.	List	-5%	On request

Part number	lx (cm ²)	ly (cm ²)	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF1945-3	6,051	1,83	3000	1,087	✓	63,72 €
Cover						
PRF1945-C		End cover with pin			✓	1,04 €

*Depending on availability - Dimensions in mm

Our other products



ACAss
Stainless steel splined shaft, Stainless steel



HTD14M_55
HTD Heavy duty timing pulley, HTD14 Steel



NCT
Square tube connector, Fixed angle



LQT
Mechanical catch, Quick closing catch angle



H1
Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHTRP
Single and dual output gearboxes, Up to 34,5 Nm



SLHHlok
Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot



BPHT
Ball transfer unit bolt fitting, Heavy



PR40
Articulated foot Ø40, Ø 40



TSP_T10P
Connecting plate for T type timing belts, T5



PSG3
Spur gear - precision range, Pre-hardened



BPL
Ball transfer unit light duty, Light

Complementary products



PRF_FIX_UNI
Universal fastener for aluminium profile, Universal



PRF19_E
Bracket for aluminium profile, PRF19 to PRF45