

R90° aluminium profile

PRF4545R90

Section: 45x45mm

- Profile for modular structures
- To be cut to length by the user
- Material:
Anodised aluminium
- Caps are not supplied individually, contact us for details

Mounting alternatives


- PRF-FIX-UNI universal fastener
- PRF19-E angle bracket
- PRF-FIX-STD standard fastener
- Screwed assemblies

Application


- For use with any type of modular construction

Advantage


- Eliminates projecting edges

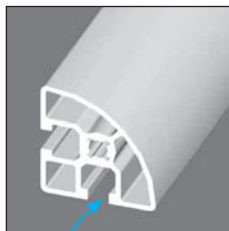

8mm slot

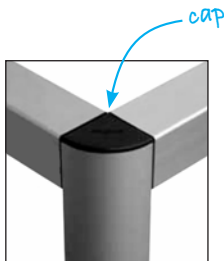

cap

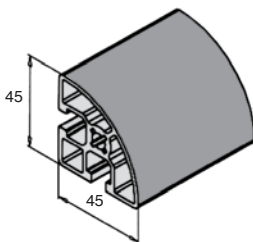

DISCOUNTS profile

Qty	1+	5+	10+
Disc.	List	-5%	On request

DISCOUNTS cap

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Ix (cm ⁴)	Iy (cm ⁴)	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF4545-3-R90	9,138	9,138	3000	1,478	4	79,98 €
Cap						
PRF4545-R90-C		End cap with pin			-	3,84 €

Dimensions in mm

Our other products



BPL

Ball transfer unit light duty, Light



ACL

Joints for aluminium profiles, Variable angle corner



RFK28C

Hypoid gearbox - Stainless steel, up to 130 Nm



OPFL_OPPM

Numerical counter accessories, Operating knob



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting



PGM52-M4

Pull handle, Brass



DB

Steel bevel gear, 2:1



TAC

Rigging screw (hook/eye), Steel



SSE

Stainless steel spherical bearing,



SUPCC

Self-centering clamping hub steel,



BLH50

Right angled gearbox, from 7.70 to 20 Nm

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



PRF_FIX_STD

Fastener for aluminium profile, Standard fastener



PRF_FIX_UNI

Universal fastener for aluminium profile, Universal