




- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- PRF90-E supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm

### Accessory

- Nut with sprung tab PRF-ECL

### Info.

- \*For applications requiring the use of a double bracket or single bracket, please contact us

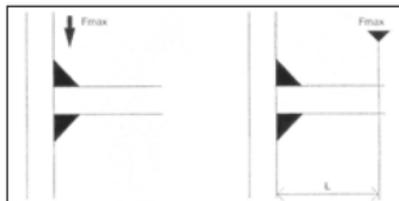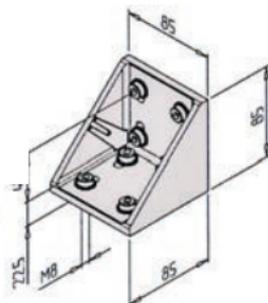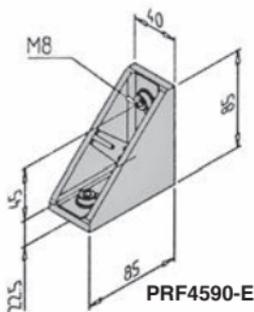

Maximum load and torque

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF4590-E	2400	800	PRF4590	20	✓	11,08 €
PRF90-E	4800	1600	PRF4590	20	✓	24,59 €

\*Depending on availability - Dimensions in mm

## Our other products



CHAR6035  
Spring hinge,  
screwed/welded



TBL  
Mini leadscrew table  
with metric thread,  
1kg



CQA20  
Accessory for  
adjustment slide-  
system, 20



SH0  
Parallel axis helical  
gear, Steel 20NCD2



CFS  
Miniature cam  
follower, Miniature



MEB  
Moulded plastic bevel  
gear (nylon), 1:1



SRG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
78mm to 90mm



PF40  
Worm and wheel gear  
reducer, up to 18 Nm



J65  
Spur gear coaxial  
gearbox, from 0.80 to  
2.95 Nm - In-line



GTC  
Belt tensioner, For  
standard applications



M0  
Worm, Hardened steel



VDSCB  
Sliding lock  
adjustment system,  
Blocking wedge for  
sliding lock for ...

## Complementary products



PRF\_ECL  
Nut for aluminium  
profile, Steel square  
nut with tab



PRF\_VTM  
Hammerhead screw,  
Hammerhead screw