

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- PRF90-E supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm







Accessory

- Nut with sprung tab PRF-ECL

Info.

- *For applications requiring the use of a double bracket or single bracket, please contact us

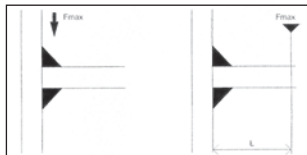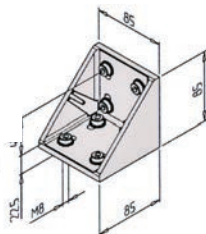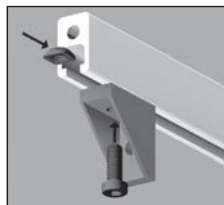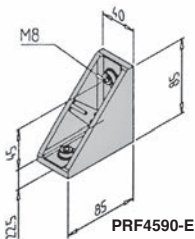

Maximum load and torque

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF4590-E	2400	800	PRF4590	20	✓	11,08 €
PRF90-E	4800	1600	PRF4590	20	✓	24,59 €

*Depending on availability - Dimensions in mm

Our other products



RLX

Free running conveyor roller, PVC



SHTP

Drylin® Linear table, Economy range



PO

Pull handle - Multi-sector, Tapped recessed insert



ACL-APB

Closing system for aluminium profile, Magnetic door stop



BMF

Knurled knob - female, Knurled - blind



PRFRTR

Cross connector for aluminium profile, Cross connector



HTD5M_25

HTD Heavy duty timing pulley, HTD5 Steel




PPD

Indexing plunger for sheets, For sheet metal



PRF4545

 Standard aluminium profile, 45 x 45 mm




LAT2

2A motorised linear actuator, 2 amperes



M0

 Worm, Non hardened steel



TIFbout

Threaded stud - DIN976A, Steel

Complementary products



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



PRF_VTM

Hammerhead screw, Hammerhead screw