

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- PRF90-E supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm







### Accessory

- Nut with sprung tab PRF-ECL

### Info.

- \*For applications requiring the use of a double bracket or single bracket, please contact us

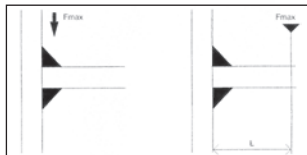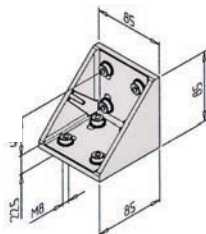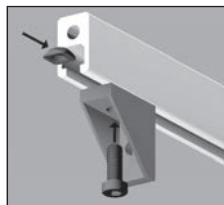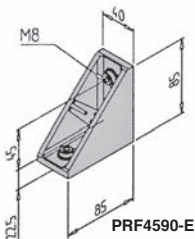

Maximum load and torque

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF4590-E	2400	800	PRF4590	20	✓	11,08 €
PRF90-E	4800	1600	PRF4590	20	✓	24,59 €

\*Depending on availability - Dimensions in mm

## Our other products



UCF

Cast iron flange bearing unit, Cast iron



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel



SMLS

Linear table, For small lengths



BSP

Compact precision slide, from 156 N to 980 N



BPF

Sheet steel flanged bearing for light loads, Sheet steel



PW\_PWG1

Wheel - precision range, Bronze



CAP882

Flexible slat top chain acetal, Large range 882



LRR

Spring loaded latch, Spring loaded latch



TCSH

Automatic chain tensioner, With



CLG1

Moulded plastic spur gear, Moulded plastic



M0

Worm and wheel set, Non hardened steel



FIRSTDC1Q60

Speed controller 10A, 10 A

## Complementary products



PRF\_ECL

Nut for aluminium profile, Steel square nut with tab



PRF\_VTM

Hammerhead screw, Hammerhead screw