

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- PRF90-E supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm






Accessory

- Nut with sprung tab PRF-ECL

Info.

- *For applications requiring the use of a double bracket or single bracket, please contact us

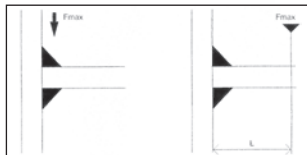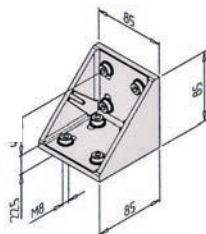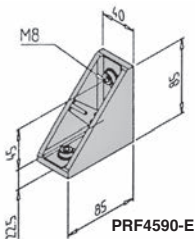

Maximum load and torque

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF4590-E	2400	800	PRF4590	20	✓	11,08 €
PRF90-E	4800	1600	PRF4590	20	✓	24,59 €

*Depending on availability - Dimensions in mm

Our other products



PCS_PA6

Plastic sprocket,
9.525mm (DIN 06B-1)



 
ACL-APB

Closing system for
aluminium profile,
Magnetic door stop



DOMI_MD

Domino rotary table,
55/1



SRF_TOOL

Assembly key for
aluminium profile,
Assembly key



NPTR_M

Adjustable cross
clamp, Adjustable



LVT

Miniature motorised
actuator 4A, 4 amperes



HW_HT

Half-rail guide, Rail




SRG

Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



ZHG6

 Plastic spur gear,
Machined plastic



KGS

Ball screw, supplied by
the metre, Rolled



BIMSS

Indexing plunger mini,
miniature - Stainless



LR

Precision locknut,
Precision locknut

Complementary products



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



PRF_VTM

Hammerhead screw,
Hammerhead screw