

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- PRF90-E supplied with cover and screw locking plate
- Material: grey powder coated aluminium GD
- Recommended tightening torque: 20Nm







Accessory

- Nut with sprung tab PRF-ECL

Info.

- *For applications requiring the use of a double bracket or single bracket, please contact us

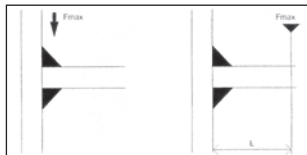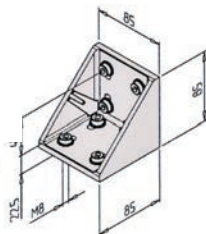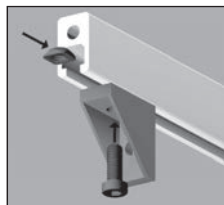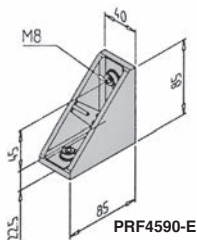

Maximum load and torque

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF4590-E	2400	800	PRF4590	20	✓	11,08 €
PRF90-E	4800	1600	PRF4590	20	✓	24,59 €

*Depending on availability - Dimensions in mm

Our other products



LVT

Miniature motorised actuator 2A, 2 ampers



CHMR110

Worm and wheel gear reducer, up to 980 Nm



PITAss

Locking bolt, with T handle




GDR880

Straight track for slat top chain, Ranges 880 and 881



ACL-PL

 Joining plate for aluminium profile, joint plate - 86x86 mm



M1

Worm and wheel set, Bronze



SBS_L

Chain link, Stainless steel



VBFP

Small 6 lobe threaded handle - female, Duroplast - Brass



SHN

Hexagonal nut DIN934, A2 Stainless steel



PTAF80-PAMF80

Articulated fixable foot with pressed base $\varnothing 80$, $\varnothing 80$



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



T5courroie

T type timing belt, T5 Steel cored polyurethane

Complementary products



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



PRF_VTM

Hammerhead screw, Hammerhead screw