

 


Dual lock for use on aluminium profile

Quick fitting, self blocking door lock

PRFSRAD

- Door or trap lock for structures assembled from PRF4545 aluminium profiles
- Mounts on central support and allows 2 doors to be locked separately
- Material: Die cast aluminium housing with black finish



No machining required




Advantages



- Easy to mount from the front using M6 CHC screws
- No drilling required
- Security feature: Cannot be removed when in locked position

Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

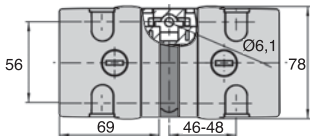

NEW!

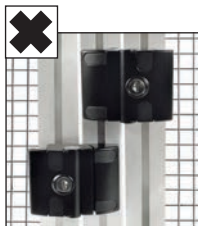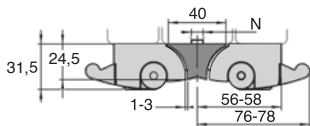

More aesthetic and more economical

DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	Type	For slot N	Weight (g)	Price each
PRF-SRAD-78-A	With universal key	8/10	235,5	62,28 €
PRF-SRAD-78-B	With individual key	8/10	235,5	62,28 €

Dimensions in mm

Our other products



LFM2

Steel leadscrew,
Medium carbon steel -
2 threads



PSG125HC

Skive hobbed spur
gears - precision
range, Case hardened
steel 20NCD2



RESC

Retractable castor for
aluminium profile,
Retractable castor



TCSH

Automatic chain
tensioner, With
support



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with nut




CHAC4040NP

Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...



CFS

Miniature cam
follower, Miniature

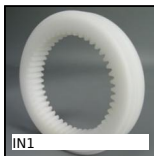


IN1

Internal gear,
Machined plastic
(delrin)



E40

 Right angle helical
reducers, from 2.30 to



T2

T type timing belt,
T2.5 Steel cored



SH2

Parallel axis helical
gear, Machined plastic



WW16

Drylin® W slide, slide
assembly

Complementary products



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



PRF4545

Standard aluminium
profile, 45 x 45 mm