

 


Dual lock for use on aluminium profile

Quick fitting, self blocking door lock

PRFSRAD

- Door or trap lock for structures assembled from PRF4545 aluminium profiles
- Mounts on central support and allows 2 doors to be locked separately
- Material: Die cast aluminium housing with black finish



No machining required




Advantages



- Easy to mount from the front using M6 CHC screws
- No drilling required
- Security feature: Cannot be removed when in locked position

Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

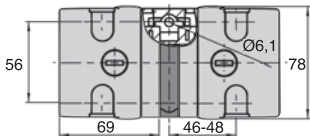

NEW!

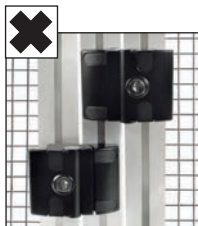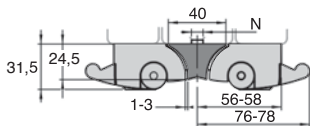

More aesthetic and more economical

DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	Type	For slot N	Weight (g)	Price each
PRF-SRAD-78-A	With universal key	8/10	235,5	62,28 €
PRF-SRAD-78-B	With individual key	8/10	235,5	62,28 €

Dimensions in mm

Our other products



PSG35
Spur gear - precision range, Stainless steel 303



GCB880
Curved track for slat top chain, Ranges 880 and 881



DER90
Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to 1.5kW



DCA
Suction cup, 1.5 bellows, natural rubber



DCG
Suction cup, 2.5 bellows, nitrile



NPCR
Adjustable cell support, Adjustable



PRF_T
Corner reinforcement, Corner reinforcement



M0
Worm and wheel set, Unhardened steel



G3
Steel spur gear, Steel 20NCD2



CHTRB
Single and dual output gearboxes, Up to 16,5 Nm



VELM6
Screw-on base for hook-and-loop strip, Polyamide



CHAEpac
Square decorative screwed hinges, carbon fibre reinforced

Complementary products



PRF_ECL
Nut for aluminium profile, Steel square nut with tab



PRF4545
Standard aluminium profile, 45 x 45 mm