

Emergency release button

PRF_{BOU}

For use with profile locks


- **Emergency release button allows security doors fitted with PRF-SRA-CAP locks to be opened**
- Secured using CHC M6 screws
- Materials:
 - Button: glass fibre reinforced PA nylon
 - Plate: chromed steel
- Working temp range: -20° to 55 °C

Advantages



- Ideal for opening the door from the inside if there is a risk of an operator becoming trapped
- Can be mounted on 30, 40, 45 or 50 mm section profiles
- Ideal accessory for the PRF-SRA-CAP lock

Accessories

- PRF-ECL-M6 screws

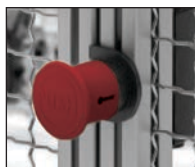

Typical application

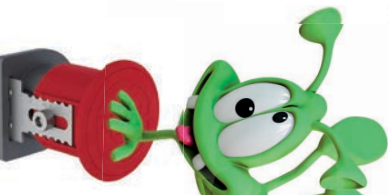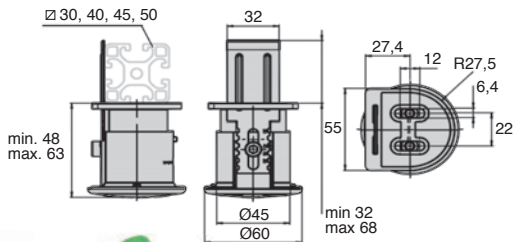

DISCOUNTS

| Qty | 1+ | 2+ | 5+ |
|------------|-----|----|------------|
| Disc. List | -5% | | On request |

| Part number | Weight (g) | Price each |
|-------------|------------|------------|
| PRF-BOU-URG | 110,8 | 31,36 € |

Dimensions in mm

Our other products



DIL

Lever operated locking bolt, lever clamp



VELprf

Clip-on base for hook-and-loop strip, Polyamide



DB

Steel bevel gear, 2:1



PAS

Pull handle, Reinforced PA thermoplastic



BPLF

Ball transfer unit light duty, Light



CHAR5050_Z

Spring hinge, screwed



HLUMss

Revolving handle for handwheel, Stainless steel 316



KITbuh

24V DC motorisation kit, Planetary gears



WJUM20

Drylin® W bearing block, Slide



SDC

Positioning sleeve for indexing pin, For pin Ø4 to Ø12



BOX-TOR-H

Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm