

Stainless steel articulated foot Ø100

PRS100

Maximum load 55.000N


- Levelling foot with solid base
- Non slip base
- Materials:
 - Base: stainless steel AISI 304
 - Threaded rod: stainless steel AISI 304 (nut not supplied)
 - Sole: NBR rubber (Shore hardness 70)

stainless steel



Advantages

- Articulated rod allows auto-alignment with the ground
- Sole material ensure

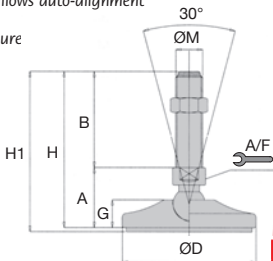

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | ØM | A | B | ØD | A/F | G | H | H1 | Max. load (N) | Price each |
|---------------|-----|----|-----|-----|-----|----|-----|-----|---------------|------------|
| | | | | | | | | | | 1 to 5 |
| PRS100-16-75 | M16 | 43 | 75 | 100 | 20 | 20 | 118 | 121 | 35000 | 103,90 € |
| PRS100-16-100 | M16 | 43 | 100 | 100 | 20 | 20 | 143 | 146 | 35000 | 107,69 € |
| PRS100-16-125 | M16 | 43 | 125 | 100 | 20 | 20 | 168 | 171 | 35000 | 110,61 € |
| PRS100-16-150 | M16 | 43 | 150 | 100 | 20 | 20 | 193 | 196 | 35000 | 113,89 € |
| PRS100-16-175 | M16 | 43 | 175 | 100 | 20 | 20 | 218 | 221 | 35000 | 116,02 € |
| PRS100-16-200 | M16 | 43 | 200 | 100 | 20 | 20 | 243 | 246 | 35000 | 122,25 € |
| PRS100-20-75 | M20 | 43 | 75 | 100 | 20 | 20 | 118 | 121 | 45000 | 103,90 € |
| PRS100-20-100 | M20 | 43 | 100 | 100 | 20 | 20 | 143 | 146 | 45000 | 100,55 € |
| PRS100-20-125 | M20 | 43 | 125 | 100 | 20 | 20 | 168 | 171 | 45000 | 110,61 € |
| PRS100-20-150 | M20 | 43 | 150 | 100 | 20 | 20 | 193 | 196 | 45000 | 113,89 € |
| PRS100-20-175 | M20 | 43 | 175 | 100 | 20 | 20 | 218 | 221 | 45000 | 116,02 € |
| PRS100-20-200 | M20 | 43 | 200 | 100 | 20 | 20 | 243 | 246 | 45000 | 122,25 € |
| PRS100-20-225 | M20 | 43 | 225 | 100 | 20 | 20 | 268 | 271 | 45000 | 125,83 € |
| PRS100-20-250 | M20 | 43 | 250 | 100 | 20 | 20 | 293 | 296 | 45000 | 130,27 € |
| PRS100-24-75 | M24 | 44 | 75 | 100 | 20 | 20 | 119 | 122 | 55000 | 103,90 € |
| PRS100-24-100 | M24 | 44 | 100 | 100 | 20 | 20 | 144 | 147 | 55000 | 107,69 € |
| PRS100-24-125 | M24 | 44 | 125 | 100 | 20 | 20 | 169 | 172 | 55000 | 110,61 € |
| PRS100-24-150 | M24 | 44 | 150 | 100 | 20 | 20 | 199 | 202 | 55000 | 113,89 € |
| PRS100-24-175 | M24 | 44 | 175 | 100 | 20 | 20 | 219 | 222 | 55000 | 116,02 € |
| PRS100-24-200 | M24 | 44 | 200 | 100 | 20 | 20 | 244 | 247 | 55000 | 122,25 € |
| PRS100-24-225 | M24 | 44 | 225 | 100 | 20 | 20 | 269 | 272 | 55000 | 125,83 € |
| PRS100-24-250 | M24 | 44 | 250 | 100 | 20 | 20 | 294 | 297 | 55000 | 130,27 € |

Dimensions in mm

Our other products




CHA1056-U4

Screwed hinge, 180°



RTK

BoWex® curved tooth gear coupling, Nylon and steel

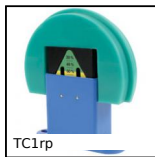

TC1rp

Automatic chain tensioner, With 180° guide



RFK28B

Hypoid gearbox - Stainless steel, up to 130 Nm



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



BLHB40

Right angled gearbox, bored shafts, up to 10.3 Nm



 
Q6

Deep groove ball bearing, Steel



CLA

Clamping lever Hygienic Usit® - female, Stainless steel



VP

Small 6 lobe threaded handle - male, Duroplast - Steel



AFSE

Locking pin with interlocking safety latch, with



DBL821

Idler for slat top chain, Range 821



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Cast

Complementary products