

Stainless steel articulated foot Ø50 Sta Stock

PRS50

Maximum load 15.000N


- Solid levelling support
- With non-slip base
- Materials:
 - Base: stainless steel AISI 304
 - Threaded rod: stainless steel AISI 304 (nut not supplied)
 - Sole: NBR rubber (Shore hardness 70)

stainless steel



Advantages

- Articulated rod allows auto-alignment with the ground
- Sole material ensures flexibility and grip

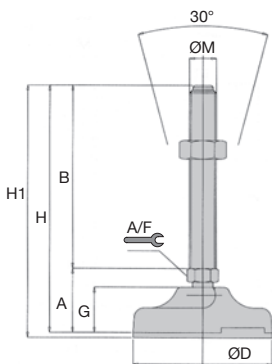

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	ØM	A	B	ØD	A/F	G	H	H1	Max. load (N)	Stock*	Price each 1 to 5
PRS50-10-50	M10	28	50	50	14	16	78	81	15000	✓	37,51 €
PRS50-10-75	M10	28	75	50	14	16	103	106	15000	✓	39,98 €
PRS50-10-100	M10	28	100	50	14	16	128	131	15000	✓	42,31 €
PRS50-10-125	M10	28	125	50	14	16	153	156	15000	✓	44,61 €
PRS50-12-50	M12	28	50	50	14	16	78	81	15000	✓	37,51 €
PRS50-12-75	M12	28	75	50	14	16	103	106	15000	✓	39,98 €
PRS50-12-100	M12	28	100	50	14	16	128	131	15000	✓	42,31 €
PRS50-12-125	M12	28	125	50	14	16	153	156	15000	✓	44,61 €
PRS50-14-50	M14	28	50	50	14	16	78	81	15000	✓	37,51 €
PRS50-14-75	M14	28	75	50	14	16	103	106	15000	✓	39,98 €
PRS50-14-100	M14	28	100	50	14	16	128	131	15000	✓	42,31 €
PRS50-14-125	M14	28	125	50	14	16	153	156	15000	✓	44,61 €

*Depending on availability - Dimensions in mm


Our other products



BDP1R
Adjustable support
arm, Single clamp



 GP75
Spring loaded toggle
latch, Standard
(GP75)




AC
Hook for latch, 20mm



M2
Worm and wheel set,
Machined plastic
(delrin)



CAP820
Slim plate chain,
Narrow straight range
820

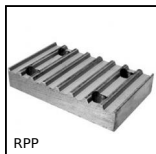

RPP
Connecting plate,
RPP8



SRP
Slotted spring pin ISO
8752, Split ISO 8752



SLHVlok
Horizontal toggle
clamp, Horizontal
toggle clamp / vertical
foot



LINK64
Synchronous AC
Motor and- gearbox ,
from 1.3 to 6Nm



ACM_AZ
Mounting bracket for
bonnet fastener, Hook



TCC
Rigging screw
(hook/hook), Steel



BLHB40
Right angled gearbox,
bored shafts, up to
10.3 Nm

Complementary products



PRS30
Articulated foot, Ø 30