


- Levelling foot with solid base
- Non slip base
- Materials:
 - Base: stainless steel AISI 304
 - Threaded rod: stainless steel AISI 304 (nut not supplied)
 - Sole: NBR rubber (Shore hardness 70)

Advantages

- Articulated rod allows auto-alignment with the ground
- Sole material ensures flexibility and grip



stainless steel

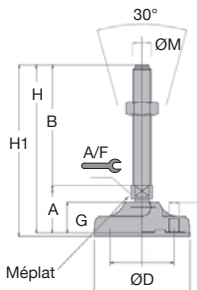

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	ØM	A	B	ØD	A/F	G	H	H1	Max. load (N)	Stock*	Price each
										✓	1 to 5
PRS80-16-50	M16	36	50	80	13	19,5	86	89	30000	✓	79,02 €
PRS80-16-75	M16	36	75	80	13	19,5	111	114	30000	-	79,87 €
PRS80-16-100	M16	36	100	80	13	19,5	136	139	30000	✓	80,82 €
PRS80-16-125	M16	36	125	80	13	19,5	159	164	30000	-	81,65 €
PRS80-16-150	M16	36	150	80	13	19,5	186	189	30000	-	82,61 €
PRS80-16-175	M16	36	175	80	13	19,5	211	214	30000	✓	83,46 €
PRS80-16-200	M16	36	200	80	13	19,5	236	239	30000	✓	84,42 €
PRS80-20-75	M20	36	75	80	13	19,5	111	114	30000	-	81,27 €
PRS80-20-100	M20	36	100	80	13	19,5	136	139	30000	-	82,16 €
PRS80-20-125	M20	36	125	80	13	19,5	161	164	30000	-	83,04 €
PRS80-20-150	M20	36	150	80	13	19,5	186	189	30000	-	83,95 €
PRS80-20-175	M20	36	175	80	13	19,5	211	214	30000	✓	84,83 €
PRS80-20-200	M20	36	200	80	13	19,5	236	239	30000	-	85,76 €
PRS80-20-225	M20	36	225	80	13	19,5	261	264	30000	-	86,65 €

*Depending on availability - Dimensions in mm

Our other products



PRF_GAL

Roller for aluminium profile, Fixing kit for roller eccentric



ASH

Hoist ring for welding, for straight lifts - for welding



MBF

Threaded blocking clamp, Threaded locking clamp



BAB

Hardened Stainless steel ball pin, Stainless steel hardened



PM4

Worm and wheel set, Bronze



BSM

Spring plunger with internal hexagonal socket, steel body, plastic pin



PSG05HC

Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)




DBC

Panamech, Multi-Beam, Aluminium - with clamping jaw




NPTF20

 Spacer for tube carrier, Fixing accessory Ø10 to Ø14



M1

 Worm and wheel set, Bronze



TBV

Manual lifting tables, For vertical strokes - Ø 16 mm column

Complementary products



PR85

Articulated foot Ø83, Ø 83