

Security pull hand

PSEC

Thermoplastic

Gripping handle for both pushing and pulling



- Blind handle, without finger hole
- Fixing with screws (not supplied)
- Working T°: -20°C to +110°C
- Material:
 - Glass fiber reinforced black thermoplastic PP
 - Orange cap RAL2004

Advantages

- The shape of the handle prevents the complete passage of the fingers and thus protects them from a shearing effect



Evite les pincements

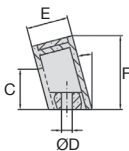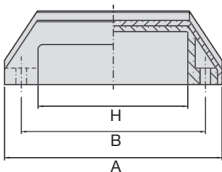

DISCOUNTING

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Référence	B	A	E	F	C	H	ØD	Weight (g)	Stock*	Price each 1 à 5
PSEC110-6	110+/-1	128	25	44	24	85	6,5	62	-	6,24 €

*Depending on availability - Dimensions in mm

Our other products



PR105

Articulated foot Ø103,
Ø 103



PLM-C

Cylindrical holding
magnets, Cylindrical
holding magnet



NPTF30

Spacer for tube
carrier, Fixing
accessory Ø14 to Ø20




PTAF100-PAMF100

Articulated fixable
foot with pressed
base Ø100, Ø 100



NSO

Housing for open
linear bearing,
Opened - long

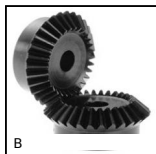

B

Steel bevel gear, 1:1



RBNpl

Fixed castor with
plate, Steel - rubber



LRX

Linear roller slide, Rail
- from 9410 N to
101000 N



MSP3815

Masterplate®
glueable insert
rectangular,



DOMI30

Domino 30 adjustable
slide, Slide DOMILINE
30 with counter and



ACL-PLAngle

Joining plate for
aluminium profile,
Angle connection



BABreglable

Adjustable ball pin
hardened stainless
steel, adjustable

Complementary products



PAP

Handle for aluminium
profile, Ergonomic
handle



PAP

Handle for aluminium
profile, Ergonomic
handle



PO

Pull handle - Multi-
sector, Smooth hole



PO

Pull handle - Multi-
sector, Tapped
recessed insert