

Security pull hand

PSEC

Thermoplastic

Gripping handle for both pushing and pulling



- Blind handle, without finger hole
- Fixing with screws (not supplied)
- Working T°: -20°C to +110°C
- Material:
 - Glass fiber reinforced black thermoplastic PP
 - Orange cap RAL2004

Advantages

- The shape of the handle prevents the complete passage of the fingers and thus protects them from a shearing effect



Evite les pincements

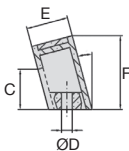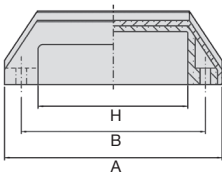


DISCOUNTING

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Référence	B	A	E	F	C	H	ØD	Weight (g)	Stock*	Price each 1 à 5
PSEC110-6	110+/-1	128	25	44	24	85	6,5	62	-	6,24 €

*Depending on availability - Dimensions in mm

 Our other products




MBrondelle

Stop washer, Stop washer MB



PW_PWG05

 Wheel - precision range, Bronze



CAB

Galvanised steel cable, Galvanised steel



MSP3815

Masterplate® glueable insert rectangular, rectangular with



SBF

Sealed flange bearing unit for Food Industry, cover



Q7

Angular contact ball bearing, Steel



FIRSTDC1Q60

Speed controller 10A, 10 A



ACLLPP

Latch for aluminium profile, Spring operated latch



DKONSL

Silicone conical elasto buffer, Male mounting



KKB-AR

Linear bearing with inclined ball tracks,



T5M_T10M

T type timing belt per metre, T5 Steel cored



BCM_T

Driving collar, Driving collar

Complementary products



PAP

Handle for aluminium profile, Ergonomic handle



PAP

Handle for aluminium profile, Ergonomic handle



PO

Pull handle - Multi-sector, Smooth hole



PO

Pull handle - Multi-sector, Tapped recessed insert