

# Security pull hand

## PSEC

## Thermoplastic

### Gripping handle for both pushing and pulling



- Blind handle, without finger hole
- Fixing with screws (not supplied)
- Working T°: -20°C to +110°C
- Material:
  - Glass fiber reinforced black thermoplastic PP
  - Orange cap RAL2004

### Advantages

- The shape of the handle prevents the complete passage of the fingers and thus protects them from a shearing effect



Evite les pincements

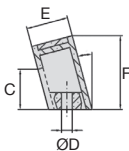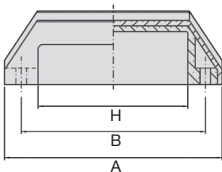

### DISCOUNTING

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Référence	B	A	E	F	C	H	ØD	Weight (g)	Stock*	Price each 1 à 5
PSEC110-6	110+/-1	128	25	44	24	85	6,5	62	-	6,24 €

\*Depending on availability - Dimensions in mm

## Our other products



DOMI120

Accessories, Clamping lever



SSE

Stainless steel spherical bearing,  
Stainless steel / PTFE



BCTH

Mushroom headed button Hygienic Usit®, With female thread and high ...



ADL\_F

Female eye bolt conforms to DIN582, Stainless steel



AC

Strike for toggle latch, 12mm



RJUM05

Drylin R® linear bearing housing, Closed - Long



PSP

Support profile, Panel support



ACLEPP

Right angled bracket for aluminium profile, 8 holes



ACLLPP

Latch for aluminium profile, Spring



NPTF20

Fixed tube carrier, Fixed Ø10 to Ø14



MFBSC

Stainless steel flexible bellows coupling,



PRF4532

Standard aluminium profile, 45 x 32 mm

## Complementary products



PAP

Handle for aluminium profile, Ergonomic handle



PAP

Handle for aluminium profile, Ergonomic handle



PO

Pull handle - Multi-sector, Smooth hole



PO

Pull handle - Multi-sector, Tapped recessed insert