

Module 0.5

Spur gear

Pre-treated or case hardened steel



- **Quality grade 7e DIN 58405 (AGMA Q10)**

- **Material :**

Pre-treated steel 35NCD6, 28HRC

Case hardened steel 20NCD2 58HRC

- Teeth profile conform to DIN 867

- Tooth thickness conforms to DIN 58405

- Efficiency approx 98%



Quality grade 7e

Options

- Alternative bores (H7)

- Keyway conforming to DIN6885 (J59)

- Tapped hole

- Hole for dowel pin

Info.

- Torque figures are for 100 rpm and are given as a guide only


- Grade and tolerances measured before heat treatment.

DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number		Z	ØP	ØD	ØA	ØM	Backlash	Torque (Nm)		Weight	Price each 1 to 5	
Standard	hardened	Teeth	Pitch	External	Bore	Boss	(mm)	Standard	hardened	Standard	hardened	
PSG0.5-20	PSG0.5-20H	20	10,0	11,0	4	8	0,076 - 0,037	0,36	1,11	0,006	30,19	€ 49,85
PSG0.5-21	PSG0.5-21H	21	10,5	11,5	4	8	0,077 - 0,036	0,37	1,16	0,006	30,50	€ 50,36
PSG0.5-22	PSG0.5-22H	22	11,0	12,0	4	8	0,077 - 0,036	0,39	1,22	0,006	30,89	€ 51,02
PSG0.5-23	PSG0.5-23H	23	11,5	12,5	4	8	0,077 - 0,036	0,41	1,27	0,006	31,25	€ 51,65
PSG0.5-24	PSG0.5-24H	24	12,0	13,0	5	10	0,077 - 0,036	0,43	1,33	0,008	31,62	€ 52,23
PSG0.5-25	PSG0.5-25H	25	12,5	13,5	5	10	0,087 - 0,042	0,44	1,38	0,009	31,92	€ 52,76
PSG0.5-26	PSG0.5-26H	26	13,0	14,0	5	10	0,087 - 0,042	0,54	1,44	0,009	32,41	€ 53,53
PSG0.5-27	PSG0.5-27H	27	13,5	14,5	5	10	0,087 - 0,042	0,57	1,50	0,009	32,75	€ 54,09
PSG0.5-28	PSG0.5-28H	28	14,0	15,0	5	10	0,087 - 0,042	0,59	1,55	0,010	33,10	€ 54,68
PSG0.5-29	PSG0.5-29H	29	14,5	15,5	6	13	0,087 - 0,042	0,61	1,61	0,013	33,31	€ 54,99
PSG0.5-30	PSG0.5-30H	30	15,0	16,0	6	13	0,087 - 0,042	0,69	1,65	0,014	33,40	€ 55,20
PSG0.5-32	PSG0.5-32H	32	16,0	17,0	6	13	0,087 - 0,042	0,74	1,76	0,015	34,24	€ 56,52
PSG0.5-35	PSG0.5-35H	35	17,5	18,5	6	13	0,087 - 0,042	0,81	1,93	0,016	35,38	€ 58,43
PSG0.5-38	PSG0.5-38H	38	19,0	20,0	6	17	0,089 - 0,041	0,87	2,09	0,026	36,45	€ 60,23
PSG0.5-40	PSG0.5-40H	40	20,0	21,0	6	17	0,089 - 0,041	1,18	2,45	0,027	37,28	€ 61,54
PSG0.5-42	PSG0.5-42H	42	21,0	22,0	6	17	0,089 - 0,041	1,24	2,57	0,028	37,94	€ 62,64
PSG0.5-45	PSG0.5-45H	45	22,5	23,5	6	17	0,089 - 0,041	1,32	2,75	0,030	39,10	€ 64,57
PSG0.5-48	PSG0.5-48H	48	24,0	25,0	6	17	0,089 - 0,041	1,41	2,94	0,032	40,68	€ 67,08
PSG0.5-50	PSG0.5-50H	50	25,0	26,0	6	17	0,089 - 0,041	1,74	3,32	0,034	41,11	€ 67,79
PSG0.5-52	PSG0.5-52H	52	26,0	27,0	6	17	0,097 - 0,046	1,81	3,45	0,035	41,73	€ 68,79
PSG0.5-55	PSG0.5-55H	55	27,5	28,5	6	17	0,097 - 0,046	1,92	3,65	0,038	42,53	€ 70,27
PSG0.5-58	PSG0.5-58H	58	29,0	30,0	6	17	0,097 - 0,046	2,02	3,85	0,040	43,40	€ 71,69
PSG0.5-60	PSG0.5-60H	60	30,0	31,0	6	17	0,097 - 0,046	2,49	4,15	0,042	43,90	€ 72,43

Dimensions in mm

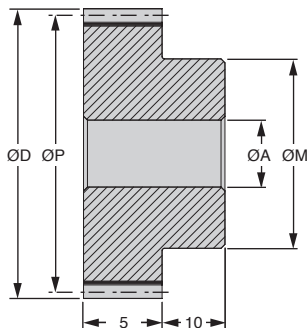

DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number	Z	OP	OD	OA	OM	Backlash	Torque (Nm)	Weight	Price each	1 to 5		
Standard	hardened	Teeth	Pitch	External	Bore	Boss	(mm)	Standard	hardened	Standard	hardened	
PSG0.5-62	PSG0.5-62H	62	31,0	32,0	8	20	0,098 - 0,044	2,57	4,29	0,048	44,42 €	73,32 €
PSG0.5-65	PSG0.5-65H	65	32,5	33,5	8	20	0,098 - 0,044	2,70	4,50	0,051	45,38 €	74,94 €
PSG0.5-68	PSG0.5-68H	68	34,0	35,0	8	20	0,098 - 0,044	2,82	4,70	0,054	45,70 €	75,43 €
PSG0.5-70	PSG0.5-70H	70	35,0	36,0	8	20	0,098 - 0,044	2,91	4,84	0,056	46,18 €	76,26 €
PSG0.5-72	PSG0.5-72H	72	36,0	37,0	8	20	0,098 - 0,044	2,99	4,98	0,058	46,65 €	76,97 €
PSG0.5-75	PSG0.5-75H	75	37,5	38,5	8	20	0,098 - 0,044	3,11	5,19	0,062	51,37 €	77,56 €
PSG0.5-78	PSG0.5-78H	78	39,0	40,0	8	20	0,098 - 0,044	3,24	5,40	0,065	47,70 €	78,70 €
PSG0.5-80	PSG0.5-80H	80	40,0	41,0	8	25	0,098 - 0,044	3,71	5,80	0,082	48,01 €	70,27 €
PSG0.5-82	PSG0.5-82H	82	41,0	42,0	8	25	0,098 - 0,044	3,81	5,95	0,084	48,55 €	80,12 €
PSG0.5-85	PSG0.5-85H	85	42,5	43,5	8	25	0,098 - 0,044	3,95	6,16	0,088	49,03 €	80,94 €
PSG0.5-90	PSG0.5-90H	90	45,0	46,0	8	25	0,098 - 0,044	4,18	6,53	0,095	49,85 €	82,29 €
PSG0.5-100	PSG0.5-100H	100	50,0	51,0	10	30	0,098 - 0,044	4,75	7,42	0,123	50,62 €	83,50 €
PSG0.5-120	PSG0.5-120H	120	60,0	61,0	10	35	0,111 - 0,049	5,70	8,90	0,177	61,33 €	101,18 €
PSG0.5-130	PSG0.5-130H	130	65,0	66,0	10	35	0,111 - 0,049	6,17	9,65	0,196	70,32 €	116,07 €
PSG0.5-140	PSG0.5-140H	140	70,0	71,0	10	35	0,111 - 0,049	6,65	10,39	0,217	73,30 €	120,91 €
PSG0.5-150	PSG0.5-150H	150	75,0	76,0	10	40	0,111 - 0,049	7,28	11,37	0,262	79,77 €	131,63 €
PSG0.5-200	PSG0.5-200H	200	100,0	101,0	14	50	0,113 - 0,047	9,80	15,32	0,444	98,33 €	162,26 €
PSG0.5-250	PSG0.5-250H	250	125,0	126,0	16	60	0,136 - 0,062	12,25	19,15	0,679	117,96 €	194,67 €

Dimensions in mm

Our other products



HS

Hexagonal spacer,
Stainless steel 303



PSG125HC

Skive hobbed spur
gears - precision
range, Case hardened
steel 20NCD2



ACLBDB

Closing mechanism
for aluminium profile,
Dual ball catch



ACLCHARJ

Hinge for aluminium
profile, Adjusts in 2
directions



SH0

Parallel axis helical
gear, Steel 20NCD2



RAG-12-M8

Roller guide
accessory, Anchoring
system



VMS

Stainless steel knurled
thumb screw, Knurled



CHA_GC_14SS

Stainless steel garnet
hinge, To screw



BMM

Knurled knob - male,
Knurled



PW_PWG15

Worm - precision
range, Stainless steel



HTD8M_30

HTD Heavy duty
timing pulley, HTD8



MHPGR

Arm with folding
rotating handle,

Complementary products



PSG05

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



PSG05S

Spur gear - precision
range, Stainless steel
303