

Module

0.8



Spur gear

Pre-treated or case hardened steel



- **Quality grade 7e DIN 58405 (AGMA Q10)**

- Material :

Pre-treated steel 35NCD6, 28HRC

Case hardened steel 20NCD2 58HRC

- Teeth profile conform to DIN 867

- Tooth thickness conforms to DIN 58405

- Efficiency approx 98%

Options

- Alternative bores (H7)

- Keyway conforming to DIN6885 (JS9)

- Tapped hole

- Hole for dowel pin

Info.

- Torque figures are for 100 rpm and are given as a guide only

- Grade and tolerances measured before heat treatment.

Quality grade 7e


DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number	Z	ØP	ØD	ØA	ØM	Backlash	Torque (Nm)	Weight	Price each	1 to 5		
Standard hardened	Teeth	Pitch	External	Bore	Boss	(mm)	Standard	Standard	Standard	Standard		
PSG0.8-18	PSG0.8-18H	18	14,4	16,0	5	11	0,096 - 0,047	0,94	3,46	0,015	29,52 €	49,49 €
PSG0.8-19	PSG0.8-19H	19	15,2	16,8	5	11	0,096 - 0,047	1,00	3,65	0,016	30,00 €	50,28 €
PSG0.8-20	PSG0.8-20H	20	16,0	17,6	5	11	0,096 - 0,047	1,33	4,53	0,017	30,43 €	51,02 €
PSG0.8-21	PSG0.8-21H	21	16,8	18,4	5	12	0,096 - 0,047	1,39	4,76	0,020	31,40 €	51,79 €
PSG0.8-22	PSG0.8-22H	22	17,6	19,2	5	12	0,096 - 0,047	1,46	4,98	0,021	31,82 €	52,57 €
PSG0.8-23	PSG0.8-23H	23	18,4	20,0	5	12	0,097 - 0,046	1,53	5,21	0,023	31,99 €	52,78 €
PSG0.8-24	PSG0.8-24H	24	19,2	20,8	6	14	0,097 - 0,046	1,59	5,44	0,026	32,13 €	53,09 €
PSG0.8-25	PSG0.8-25H	25	20,0	21,6	6	14	0,097 - 0,046	1,66	5,66	0,028	33,50 €	55,31 €
PSG0.8-26	PSG0.8-26H	26	20,8	22,4	6	14	0,097 - 0,046	2,03	5,90	0,029	34,71 €	57,29 €
PSG0.8-27	PSG0.8-27H	27	21,6	23,2	6	14	0,097 - 0,046	2,11	6,13	0,031	35,38 €	58,43 €
PSG0.8-28	PSG0.8-28H	28	22,4	24,0	8	18	0,097 - 0,046	2,18	6,35	0,037	36,21 €	59,79 €
PSG0.8-29	PSG0.8-29H	29	23,2	24,8	8	18	0,097 - 0,046	2,26	6,58	0,039	37,16 €	61,33 €
PSG0.8-30	PSG0.8-30H	30	24,0	25,6	8	18	0,097 - 0,046	2,58	6,76	0,041	37,77 €	62,34 €
PSG0.8-32	PSG0.8-32H	32	25,6	27,2	8	18	0,108 - 0,052	2,75	7,21	0,045	38,74 €	64,00 €
PSG0.8-35	PSG0.8-35H	35	28,0	29,6	10	20	0,108 - 0,052	3,00	7,89	0,052	40,05 €	66,12 €
PSG0.8-38	PSG0.8-38H	38	30,4	32,0	10	20	0,109 - 0,050	3,26	8,57	0,059	41,73 €	68,82 €
PSG0.8-40	PSG0.8-40H	40	32,0	33,6	10	20	0,109 - 0,050	4,39	10,03	0,064	43,23 €	71,38 €
PSG0.8-42	PSG0.8-42H	42	33,6	35,2	10	20	0,109 - 0,050	4,61	10,53	0,069	43,55 €	71,89 €
PSG0.8-45	PSG0.8-45H	45	36,0	37,6	10	20	0,109 - 0,050	4,94	11,28	0,077	44,17 €	72,95 €
PSG0.8-48	PSG0.8-48H	48	38,4	40,0	10	30	0,109 - 0,050	5,26	12,04	0,117	44,53 €	73,54 €
PSG0.8-50	PSG0.8-50H	50	40,0	41,6	10	30	0,109 - 0,050	6,50	13,61	0,123	53,78 €	81,18 €
PSG0.8-52	PSG0.8-52H	52	41,6	43,2	10	30	0,109 - 0,050	6,76	14,15	0,129	50,66 €	83,60 €
PSG0.8-55	PSG0.8-55H	55	44,0	45,6	10	30	0,109 - 0,050	7,15	14,97	0,139	52,73 €	87,07 €
PSG0.8-58	PSG0.8-58H	58	46,4	48,0	10	30	0,109 - 0,050	7,54	15,78	0,150	54,35 €	89,70 €

Dimensions in mm

Module 0.8

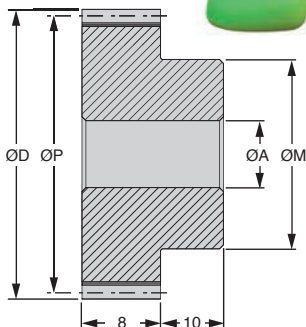

DISCOUNTS

Qty	1+	6+	19+	50+
Disc. List	-5%	-10%	On request	

Part number	Z	OP	OD	OA	OM	Backlash	Torque (Nm)	Weight	Price each 1 to 5			
Standard hardened	Teeth	Pitch	External	Bore	Boss	(mm)	Standard hardened	Standard hardened	Standard hardened			
PSG0.8-60	PSG0.8-60H	60	48,0	49,6	10	40	0,109 - 0,050	9,29	17,00	0,200	55,62 €	91,79 €
PSG0.8-62	PSG0.8-62H	62	49,6	51,2	10	40	0,109 - 0,050	9,60	17,57	0,208	57,44 €	94,83 €
PSG0.8-65	PSG0.8-65H	65	52,0	53,6	10	40	0,122 - 0,055	10,06	18,42	0,220	61,58 €	101,58 €
PSG0.8-68	PSG0.8-68H	68	54,4	56,0	10	40	0,122 - 0,055	10,52	19,27	0,233	64,69 €	106,83 €
PSG0.8-70	PSG0.8-70H	70	56,0	57,6	10	40	0,122 - 0,055	10,83	19,83	0,241	66,07 €	109,04 €
PSG0.8-72	PSG0.8-72H	72	57,6	59,2	10	40	0,122 - 0,055	11,14	20,40	0,250	67,49 €	111,40 €
PSG0.8-75	PSG0.8-75H	75	60,0	61,6	10	50	0,122 - 0,055	11,61	21,25	0,320	72,01 €	118,86 €
PSG0.8-78	PSG0.8-78H	78	62,4	64,0	10	50	0,122 - 0,055	12,07	22,10	0,334	73,08 €	120,64 €
PSG0.8-80	PSG0.8-80H	80	64,0	65,6	10	50	0,122 - 0,055	15,21	23,77	0,344	74,60 €	123,08 €
PSG0.8-82	PSG0.8-82H	82	65,6	67,2	10	50	0,122 - 0,055	15,59	24,36	0,354	75,61 €	124,85 €
PSG0.8-85	PSG0.8-85H	85	68,0	69,6	10	50	0,122 - 0,055	16,16	25,25	0,370	77,27 €	127,52 €
PSG0.8-90	PSG0.8-90H	90	72,0	73,6	10	65	0,122 - 0,055	17,11	26,74	0,504	79,74 €	131,61 €
PSG0.8-95	PSG0.8-95H	95	76,0	77,6	10	65	0,122 - 0,055	18,06	28,22	0,533	88,27 €	145,72 €
PSG0.8-100	PSG0.8-100H	100	80,0	81,6	14	65	0,122 - 0,055	19,45	30,39	0,553	89,45 €	147,65 €
PSG0.8-110	PSG0.8-110H	110	88,0	89,6	14	70	0,123 - 0,053	20,42	31,91	0,661	112,01 €	184,85 €
PSG0.8-120	PSG0.8-120H	120	96,0	97,6	14	70	0,123 - 0,053	21,40	33,43	0,733	126,67 €	209,01 €

Dimensions in mm

Our other products



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



DOMI80

Accessories, Clamping lever



GPB

Threaded spherical knob, Moulded thread



DB

Steel bevel gear, 2:1



RTE

Rotex®, jaw coupling, Aluminium



BPPE

Ball transfer unit push fit, Light



PSPT

Flexible tube handle, PVC



DIL

Lever operated locking bolt, lever clamp




GG3

Ground spur gear, Heat treated steel



E60

Right angle helical reducers, from 4.50 to 62 Nm

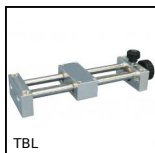

TBL

Mini leadscrew table with metric thread, 1kg



ACLBS

Spherical ended stop for aluminium profile, Spherical ended stop

Complementary products